
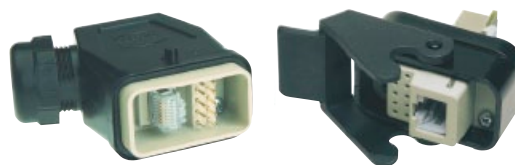
 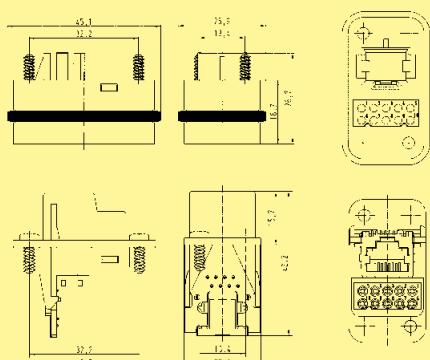


Number of contacts

8



Identification	Part number		Drawing	Dimensions in mm
	Male insert (M)	Female insert (F)		
Han® Q Data RJ45 Order crimp contacts separately female insert usable for panel feed through for patch cables	09 12 011 3001	09 12 011 3111		

Identification	Wire gauge (mm²)	Part number		Drawing	Dimensions in mm												
		Male contact	Female contact														
Individual contacts																	
Han® D-Sub contacts gold plated																	
	0.13-0.33 0.33-0.52	61 03 000 0094 61 03 000 0073	61 03 000 0096 61 03 000 0074	<table><tr><th colspan="2">Wire gauge</th><th>Ø</th><th>Stripping length</th></tr><tr><td>0.13-0.33 mm²</td><td>AWG 26-22</td><td>0.9</td><td>5 mm</td></tr><tr><td>0.33-0.52 mm²</td><td>AWG 22-20</td><td>1.12</td><td>5 mm</td></tr></table>		Wire gauge		Ø	Stripping length	0.13-0.33 mm²	AWG 26-22	0.9	5 mm	0.33-0.52 mm²	AWG 22-20	1.12	5 mm
Wire gauge		Ø	Stripping length														
0.13-0.33 mm²	AWG 26-22	0.9	5 mm														
0.33-0.52 mm²	AWG 22-20	1.12	5 mm														
RJ45 plug AMP (for replacement)																	
AWG 24 ... 26 Ø 0.89 mm ... 0.99 mm		09 12 000 9958															

Stock items in bold type

Han
Q