


Number of contacts

12 +

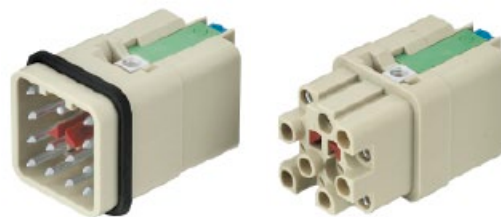

Identification	Part number		Drawing	Dimensions in mm
	Male insert (M)	Female insert (F)		
<p>Crimp termination/ Han-Quick Lock® Order crimp contacts separately</p> <p>PE contact: Quick Lock termination</p>	<b>09 12 012 3001</b>	<b>09 12 012 3101</b>		
<p>Coding pins</p>	<b>09 12 000 9924</b>	<b>09 12 000 9924</b>		<p>Range of delivery: 20 pieces per frame</p>

Han Q

Identification	Wire gauge (mm²)	Part number		Drawing	Dimensions in mm																																			
		Male contact	Female contact																																					
<p>Crimp contacts</p> <p>Power contacts silver plated</p> <p>gold plated</p>	<p>0.14-0.37</p> <p>0.5</p> <p>0.75</p> <p>1</p> <p>1.5</p> <p>2.5</p> <p>0.14-0.37</p> <p>0.5</p> <p>0.75</p> <p>1</p> <p>1.5</p> <p>2.5</p>	<p><b>09 15 000 6104</b></p> <p><b>09 15 000 6103</b></p> <p><b>09 15 000 6105</b></p> <p><b>09 15 000 6102</b></p> <p><b>09 15 000 6101</b></p> <p><b>09 15 000 6106</b></p> <p><b>09 15 000 6124</b></p> <p><b>09 15 000 6123</b></p> <p><b>09 15 000 6125</b></p> <p><b>09 15 000 6122</b></p> <p><b>09 15 000 6121</b></p> <p><b>09 15 000 6126</b></p>	<p><b>09 15 000 6204</b></p> <p><b>09 15 000 6203</b></p> <p><b>09 15 000 6205</b></p> <p><b>09 15 000 6202</b></p> <p><b>09 15 000 6201</b></p> <p><b>09 15 000 6206</b></p> <p><b>09 15 000 6224</b></p> <p><b>09 15 000 6223</b></p> <p><b>09 15 000 6225</b></p> <p><b>09 15 000 6222</b></p> <p><b>09 15 000 6221</b></p> <p><b>09 15 000 6226</b></p>	<table border="1"> <thead> <tr> <th colspan="3">Wire gauge</th> <th>∅</th> <th>Stripping length</th> </tr> </thead> <tbody> <tr> <td>0.14-0.37</td> <td>mm²</td> <td>AWG 26-22</td> <td>0.9</td> <td>8 mm</td> </tr> <tr> <td>0.5</td> <td>mm²</td> <td>AWG 20</td> <td>1.1</td> <td>8 mm</td> </tr> <tr> <td>0.75</td> <td>mm²</td> <td>AWG 18</td> <td>1.3</td> <td>8 mm</td> </tr> <tr> <td>1</td> <td>mm²</td> <td>AWG 18</td> <td>1.45</td> <td>8 mm</td> </tr> <tr> <td>1.5</td> <td>mm²</td> <td>AWG 16</td> <td>1.75</td> <td>8 mm</td> </tr> <tr> <td>2.5</td> <td>mm²</td> <td>AWG 14</td> <td>2.25</td> <td>6 mm</td> </tr> </tbody> </table>	Wire gauge			∅	Stripping length	0.14-0.37	mm²	AWG 26-22	0.9	8 mm	0.5	mm²	AWG 20	1.1	8 mm	0.75	mm²	AWG 18	1.3	8 mm	1	mm²	AWG 18	1.45	8 mm	1.5	mm²	AWG 16	1.75	8 mm	2.5	mm²	AWG 14	2.25	6 mm	
Wire gauge			∅	Stripping length																																				
0.14-0.37	mm²	AWG 26-22	0.9	8 mm																																				
0.5	mm²	AWG 20	1.1	8 mm																																				
0.75	mm²	AWG 18	1.3	8 mm																																				
1	mm²	AWG 18	1.45	8 mm																																				
1.5	mm²	AWG 16	1.75	8 mm																																				
2.5	mm²	AWG 14	2.25	6 mm																																				
<p>F.O. contacts for 1 mm plastic fibre</p>		<b>20 10 001 3211</b>	<b>20 10 001 3221</b>																																					