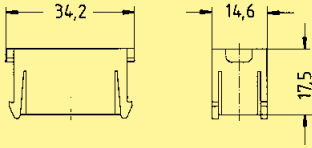
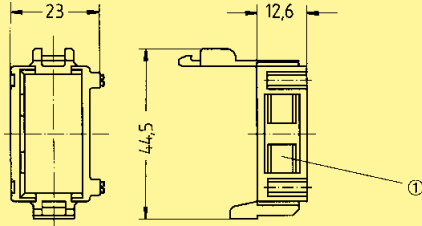
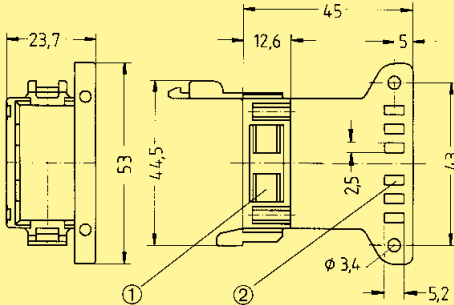
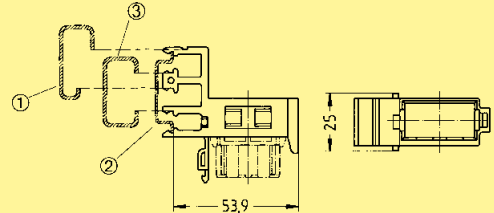
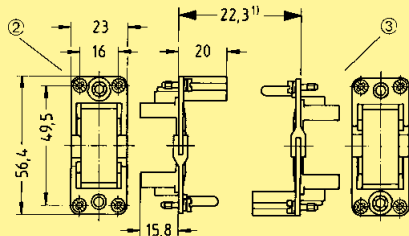


Identification	Part number	Drawing	Dimensions in mm
Han-Modular® Dummy module to fill up module spaces not in use in the frame 	09 14 000 9950		
Module clamp without strain relief *  Delivery comprises one module clamp.	09 14 000 0311	 1 Slot for identification strip	
Module clamp with strain relief *  Delivery comprises one module clamp.	09 14 000 0312	 1 Slot for identification strip 2 For cable ties with max. 5 mm width	
Module clamp for rail *  Delivery comprises one module clamp.	09 14 000 0313	 1 G-rail DIN EN 60 715-G32 2 rail DIN EN 60 715-35 x 7.5 with 1 mm thickness or -35 x 15 with 1.5 mm thickness 3 C-rail DIN EN 60 715-C30	
Frame for 1 module  in housing Han® 10 A	09 14 000 0304	 1 Distance max. 23.5 mm 2 Hoods 3 Housings	

* Suitable for the single modules Han® C Crimp, Han® C Axial, Han E® Crimp, Han EE®, Han E® Protected, Han DD® Crimp, Han® High Density, Han® USB, Han® Firewire, Han® Multi module and Han® SC