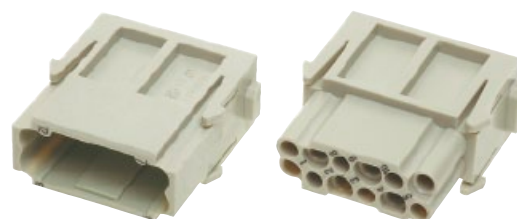


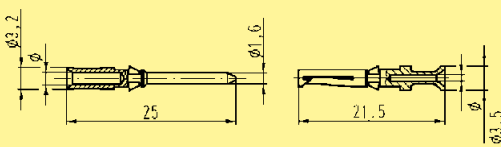
 
Number of contacts

12



Identification	Part number		Drawing	Dimensions in mm
	Male insert (M)	Female insert (F)		
Crimp terminal Order crimp contacts separately	09 14 012 3001	09 14 012 3101	Contact arrangement view from termination side	

Han
Modular

Identification	Wire gauge (mm ²)	Part number		Drawing	Dimensions in mm	
		Male contact	Female contact			
Crimp contacts						
Power contacts						
silver plated	0.14-0.37	09 15 000 6104	09 15 000 6204			
	0.5	09 15 000 6103	09 15 000 6203			
	0.75	09 15 000 6105	09 15 000 6205			
	1	09 15 000 6102	09 15 000 6202			
	1.5	09 15 000 6101	09 15 000 6201			
	2.5	09 15 000 6106	09 15 000 6206			
gold plated	0.14-0.37	09 15 000 6124	09 15 000 6224			
	0.5	09 15 000 6123	09 15 000 6223			
	0.75	09 15 000 6125	09 15 000 6225			
	1	09 15 000 6122	09 15 000 6222			
	1.5	09 15 000 6121	09 15 000 6221			
	2.5	09 15 000 6126	09 15 000 6226			
F.O. contacts						
for 1 mm plastic fibre						
		20 10 001 3211	20 10 001 3221			
						

Stock items in bold type