
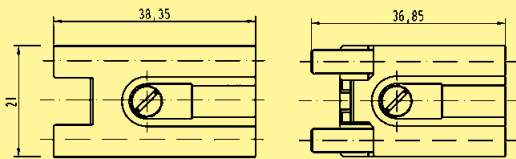
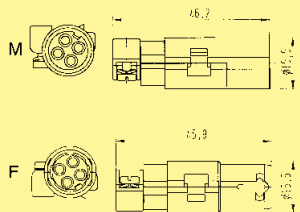


4 contacts + shielding
+ 2 power contacts
suitable in Han® 3 A metric
hoods and housings

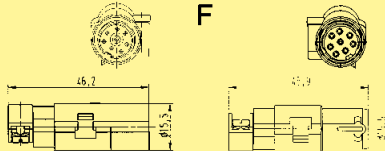

Identification	Part number		Drawing	Dimensions in mm
	Male insert (M)	Female insert (F)		
Quintax insert 	09 15 003 3001	09 15 003 3101		

Identification	Wire gauge (mm²)	Part number		Drawing	Dimensions in mm
		Male contact	Female contact		
Han-Quintax® contact 4 + shielding Han D® crimp contacts 		09 15 004 3013	09 15 004 3113		
Han D® Crimp contact gold plated 	0,14-0,37 0,5 0,75 1 1,5 2,5	09 15 000 6124 09 15 000 6123 09 15 000 6125 09 15 000 6122 09 15 000 6121 09 15 000 6126	09 15 000 6224 09 15 000 6223 09 15 000 6225 09 15 000 6222 09 15 000 6221 09 15 000 6226		

High Density Quintax contact 8 + shielding Han® D-Sub contacts 		09 15 008 3013	09 15 008 3113		
D-Sub crimp contact 	0,08-0,21 0,13-0,33 0,33-0,52	61 03 000 0078 61 03 000 0094 61 03 000 0073	61 03 000 0080 61 03 000 0096 61 03 000 0074		

Stock items in bold type