


Number of contacts

2

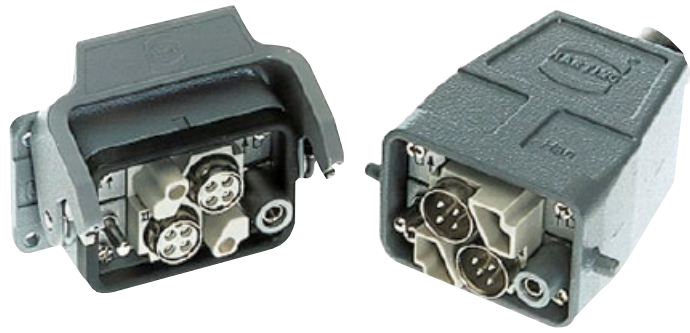

Identification	Part number		Drawing	Dimensions in mm
	Male insert (M)	Female insert (F)		
<p>Crimp terminal</p>	09 14 002 3001	09 14 002 3101	<p>M</p> <p>F</p> <p>Contact arrangement view from termination side</p>	
<p>Quintax metal adapter option</p>	09 14 000 9915	09 14 000 9915		

Han Modular

Identification	Wire gauge (mm ²)	Part number		Drawing	Dimensions in mm												
		Male contact	Female contact														
<p>Quintax contact 4 + shielding Han D® crimp contacts</p>		09 15 004 3013	09 15 004 3113														
<p>Han D® Crimp contact gold plated</p>	0.14-0.37 0.5 0.75 1 1.5 2.5	09 15 000 6124 09 15 000 6123 09 15 000 6125 09 15 000 6122 09 15 000 6121 09 15 000 6126	09 15 000 6224 09 15 000 6223 09 15 000 6225 09 15 000 6222 09 15 000 6221 09 15 000 6226														
<p>High Density Quintax contact 8 + shielding Han® D-Sub contacts</p>		09 15 008 3013	09 15 008 3113														
<p>D-Sub crimp contact</p>	0.08-0.21 0.13-0.33 0.21-0.52	09 67 000 7576 09 67 000 5576 09 67 000 8576	09 67 000 7476 09 67 000 5476 09 67 000 8476	<table border="1"> <thead> <tr> <th colspan="2">Wire gauge</th> <th>Stripping length</th> </tr> </thead> <tbody> <tr> <td>0,08-0,21 mm²</td> <td>AWG 28-24</td> <td>4 mm</td> </tr> <tr> <td>0,13-0,33 mm²</td> <td>AWG 26-22</td> <td>4 mm</td> </tr> <tr> <td>0,21-0,52 mm²</td> <td>AWG 24-20</td> <td>4 mm</td> </tr> </tbody> </table>	Wire gauge		Stripping length	0,08-0,21 mm ²	AWG 28-24	4 mm	0,13-0,33 mm ²	AWG 26-22	4 mm	0,21-0,52 mm ²	AWG 24-20	4 mm	
Wire gauge		Stripping length															
0,08-0,21 mm ²	AWG 28-24	4 mm															
0,13-0,33 mm ²	AWG 26-22	4 mm															
0,21-0,52 mm ²	AWG 24-20	4 mm															

Order crimp contacts separately

Stock items in bold type