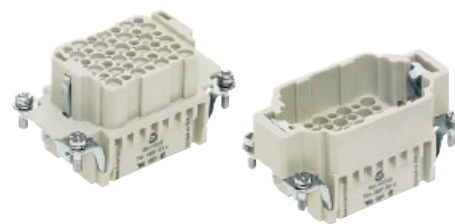


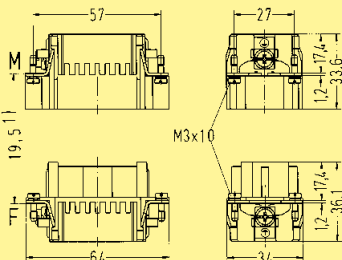
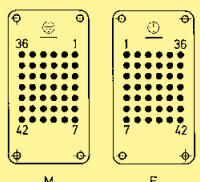
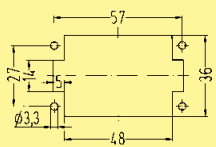
Number of contacts

42 +



Inserts

Han
D/DD

Identification	Series	Part number		Drawing	Dimensions in mm
		Male insert (M)	Female insert (F)		
Crimp terminal Order crimp contacts separately (see Technical characteristics on page 02.06) 	Han DD®	09 16 042 3001	09 16 042 3101	 1) Distance for contact max. 21 mm Contact arrangement view from termination side  Panel cut out for inserts for use without hoods/housings 	
Coding pin 					
			09 33 000 9915	Coding pin  Use of the coding pin prevents incorrect mating to other connectors of the same type. The male pin should be omitted from the opposing cavity in the male insert.	