
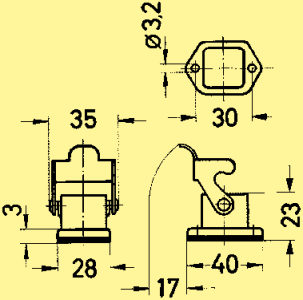

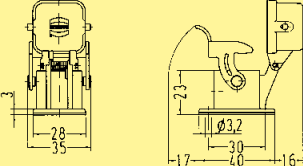

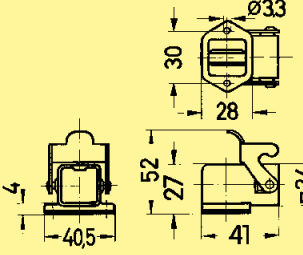

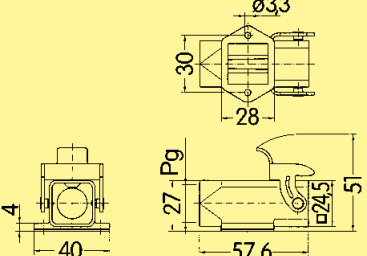

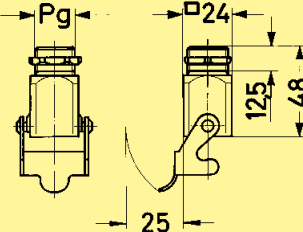


Metal hoods/housings for industrial applications / 1 lever locking system

Identification	Part number	Pg	Drawing	Dimensions in mm
Housings, bulkhead mounting	 <b>09 20 003 0301</b>		 Panel cut out 22 x 22 mm	
	 09 20 003 0305 <sup>2)</sup> <b>09 20 003 0306<sup>1)</sup></b>		 Panel cut out 22 x 22 mm	
	 <b>09 20 003 0801</b>		 Panel cut out 22 x 22 mm	
Housings, surface mounting top entry	 <b>09 20 003 1250</b> bottom closed <b>09 20 003 1252</b>	1 x 11  1 x 11	 Panel cut out 22 x 22 mm	
Housings, screw mounting top entry	 <b>09 20 003 0102</b>	1 x 13.5		

Han Hoods Housings

<sup>1)</sup> for mounted female insert  
<sup>2)</sup> for mounted male insert

Stock items in bold type