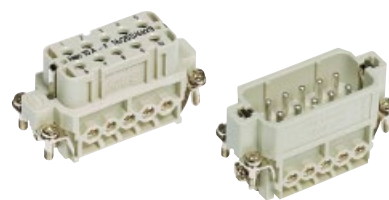
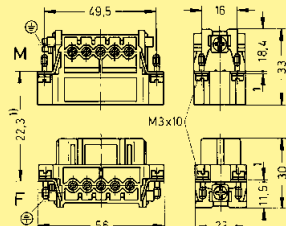
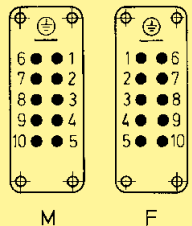
 
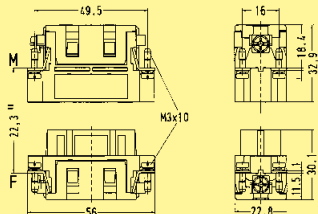


Number of contacts

10 +

Han
A

Inserts

Identification	Series	Part number		Drawing	Dimensions in mm
		Male insert (M)	Female insert (F)		
Screw terminal 	Han A®	09 20 010 2612	09 20 010 2812	Screw terminal  1) Distance for contact max. 24 mm	
Crimp terminal Order crimp contacts separately (see Technical characteristics on page 01.03) 	Han A®	09 20 010 3001	09 20 010 3101	Contact arrangement view from termination side  Panel cut out for inserts for use without hoods/housings  Crimp terminal  1) Distance for contact max. 24 mm	