

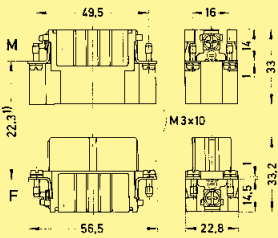
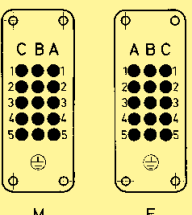
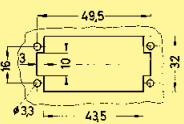
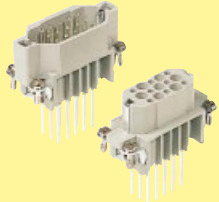
Number of contacts

15 +



Inserts

Han
D/DD

Identification	Series	Part number		Drawing	Dimensions in mm
		Male insert (M)	Female insert (F)		
Crimp terminal Order crimp contacts separately (see Technical characteristics on page 02.04) 	Han D®	09 21 015 3001	09 21 015 3101	 1) Distance for contact max. 24 mm Contact arrangement view from termination side  Panel cut out for inserts for use without hoods/housings 	
Wrap terminal 1 x 1 mm 		09 21 015 2601	09 21 015 2701	Coding pin  09 33 000 9915 Use of the coding pin prevents incorrect mating to other connectors of the same type. The male pin should be omitted from the opposing cavity in the male insert.	