



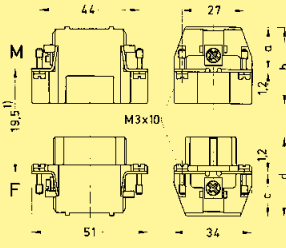
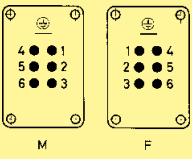
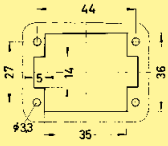



Number of contacts

6 +

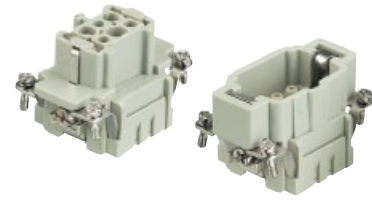

Inserts

Han E/EE

| Identification | Series | Part number | | Drawing | Dimensions in mm | | | | | | | | | | | | | | | | | | | | |
|---------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|----------|-----------------------|-----------------------|------------------------------------------------------------------------------------|----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|--|---|---|---|---|--------------|----|----|----|----|------------------------|----|----|----|----|----------|----|----|----|----|
| | | Male insert (M) | Female insert (F) | | | | | | | | | | | | | | | | | | | | | | |
| <p>Crimp terminal</p> <p>Order crimp contacts separately (see Technical characteristics on page 03.03)</p>  | Han E® | 09 33 006 2602 | 09 33 006 2702 |  | <p>1) Distance for contact max. 21 mm</p> <table border="1"> <thead> <tr> <th></th> <th>a</th> <th>b</th> <th>c</th> <th>d</th> </tr> </thead> <tbody> <tr> <td>Han E® screw</td> <td>18</td> <td>33</td> <td>18</td> <td>35</td> </tr> <tr> <td>Han® ES / Han E® crimp</td> <td>19</td> <td>34</td> <td>19</td> <td>36</td> </tr> <tr> <td>Han® ESS</td> <td>34</td> <td>49</td> <td>32</td> <td>49</td> </tr> </tbody> </table> <p>Contact arrangement view from termination side</p>  <p>Panel cut out</p>  | | a | b | c | d | Han E® screw | 18 | 33 | 18 | 35 | Han® ES / Han E® crimp | 19 | 34 | 19 | 36 | Han® ESS | 34 | 49 | 32 | 49 |
| | a | b | c | d | | | | | | | | | | | | | | | | | | | | | |
| Han E® screw | 18 | 33 | 18 | 35 | | | | | | | | | | | | | | | | | | | | | |
| Han® ES / Han E® crimp | 19 | 34 | 19 | 36 | | | | | | | | | | | | | | | | | | | | | |
| Han® ESS | 34 | 49 | 32 | 49 | | | | | | | | | | | | | | | | | | | | | |
| <p>Screw terminal with wire protection</p>  | Han E® | 09 33 006 2601 | 09 33 006 2701 | | | | | | | | | | | | | | | | | | | | | | |
| <p>Cage-clamp terminal</p>  | Han® ES | 09 33 006 2616 | 09 33 006 2716 | | | | | | | | | | | | | | | | | | | | | | |
| <p>Cage-clamp terminal two terminals per contact</p>  | Han® ESS | 09 33 006 2672 | 09 33 006 2772 | | | | | | | | | | | | | | | | | | | | | | |