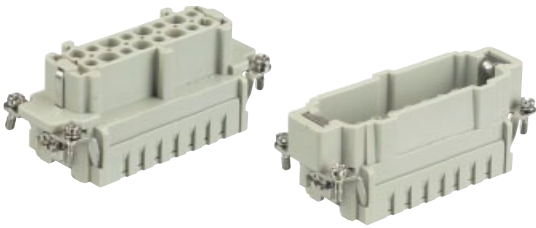


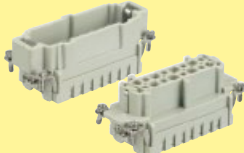
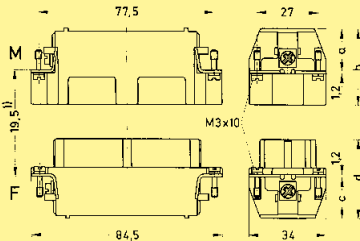
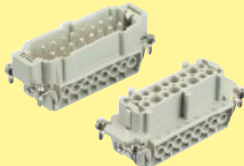
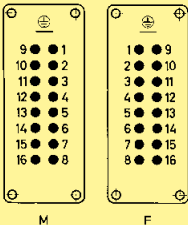
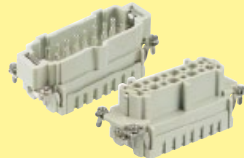
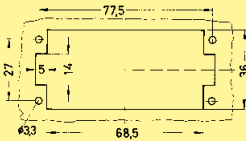
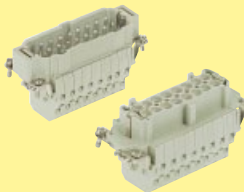


Number of contacts

16 +



Inserts

Identification	Series	Male insert (M)	Female insert (F)	Drawing	Dimensions in mm																				
Crimp terminal Order crimp contacts separately (see Technical characteristics on page 03.03) 	Han E®	09 33 016 2602	09 33 016 2702		1) Distance for contact max. 21 mm																				
Screw terminal with wire protection 	Han E®	09 33 016 2601	09 33 016 2701	<table border="1"><thead><tr><th></th><th>a</th><th>b</th><th>c</th><th>d</th></tr></thead><tbody><tr><td>Han E® screw</td><td>18</td><td>33</td><td>18</td><td>35</td></tr><tr><td>Han® ES / Han E® crimp</td><td>19</td><td>34</td><td>19</td><td>36</td></tr><tr><td>Han® ESS</td><td>34</td><td>49</td><td>32</td><td>49</td></tr></tbody></table> Contact arrangement view from termination side 		a	b	c	d	Han E® screw	18	33	18	35	Han® ES / Han E® crimp	19	34	19	36	Han® ESS	34	49	32	49	
	a	b	c	d																					
Han E® screw	18	33	18	35																					
Han® ES / Han E® crimp	19	34	19	36																					
Han® ESS	34	49	32	49																					
Cage-clamp terminal 	Han® ES	09 33 016 2616	09 33 016 2716	Panel cut out 																					
Cage-clamp terminal two terminals per contact 	Han® ESS	09 33 016 2672	09 33 016 2772																						

Stock items in bold type