
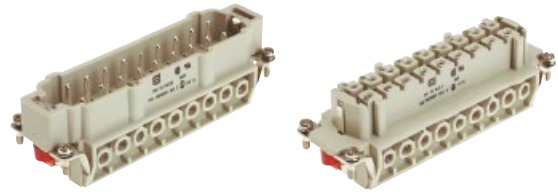
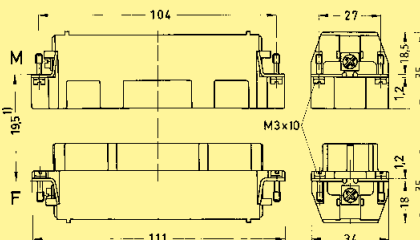


Number of contacts

16 + ☰

+ 2 additional contacts for
safe high voltage connections

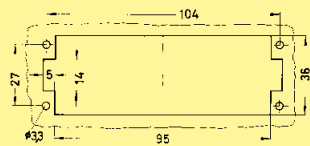

Part number																																																																												
Identification	Series	Male insert (M)	Female insert (F)	Drawing																																																																								
Screw terminal	Han Hv E®																																																																											
	1-16	09 34 016 2601	09 34 016 2701	 1) Distance for contact max. 21 mm Contact arrangement (view from termination side) Han® 16 Hv E <table><tr><th colspan="3">M</th><th colspan="3">F</th></tr><tr><td>⊕</td><td>⊖</td><td></td><td>⊕</td><td>⊖</td><td></td></tr><tr><td>A</td><td>1</td><td>●</td><td>1</td><td>●</td><td>A</td></tr><tr><td>10</td><td>2</td><td>●</td><td>2</td><td>●</td><td>10</td></tr><tr><td>11</td><td>3</td><td>●</td><td>3</td><td>●</td><td>11</td></tr><tr><td>12</td><td>4</td><td>●</td><td>4</td><td>●</td><td>12</td></tr><tr><td>13</td><td>5</td><td>●</td><td>5</td><td>●</td><td>13</td></tr><tr><td>14</td><td>6</td><td>●</td><td>6</td><td>●</td><td>14</td></tr><tr><td>15</td><td>7</td><td>●</td><td>7</td><td>●</td><td>15</td></tr><tr><td>16</td><td>8</td><td>●</td><td>8</td><td>●</td><td>16</td></tr><tr><td>B</td><td>9</td><td>○</td><td>9</td><td>○</td><td>B</td></tr><tr><td>⊖</td><td>⊕</td><td></td><td>⊖</td><td>⊕</td><td></td></tr></table> ● Working contact ⦿ Relay contact ○ Without contact Panel cut out for inserts for use without hoods/ housings 	M			F			⊕	⊖		⊕	⊖		A	1	●	1	●	A	10	2	●	2	●	10	11	3	●	3	●	11	12	4	●	4	●	12	13	5	●	5	●	13	14	6	●	6	●	14	15	7	●	7	●	15	16	8	●	8	●	16	B	9	○	9	○	B	⊖	⊕		⊖	⊕	
M			F																																																																									
⊕	⊖		⊕	⊖																																																																								
A	1	●	1	●	A																																																																							
10	2	●	2	●	10																																																																							
11	3	●	3	●	11																																																																							
12	4	●	4	●	12																																																																							
13	5	●	5	●	13																																																																							
14	6	●	6	●	14																																																																							
15	7	●	7	●	15																																																																							
16	8	●	8	●	16																																																																							
B	9	○	9	○	B																																																																							
⊖	⊕		⊖	⊕																																																																								