

Han® PushPull, type acc. to IEC 61 076-3-117 variant 14
Housing bulkhead mounting for device integration and RJ45 jacks

Features

- HARTING PushPull technology
- Compact design
- High packing density
- Device integration via RJ45 PCB connectors

Technical characteristics

Locking	PushPull technology acc. to IEC 61 076-3-117
Degree of protection	IP 65 / IP 67
Mating face	RJ45 acc. to IEC 60 603-7
Termination type	Jack with solder termination
Mating cycles	min. 750
Temperature range	-40 °C ... +70 °C
Housing material	Plastic, black
Flammability acc. to UL 94	V 0

Identification

Part No.


Drawing

Dimensions in mm

Components device side

Housing bulkhead mounting plastic

09 35 002 0321

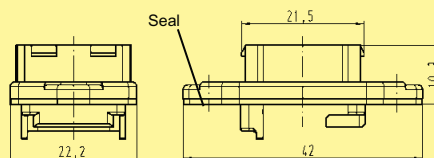

Dust protection cover IP 40 rubber (NBR)

09 35 002 5401


Protection cover IP 65 / IP 67

09 35 002 5402

RJ45 jack


Solder variant, 90° angled

09 35 002 2101

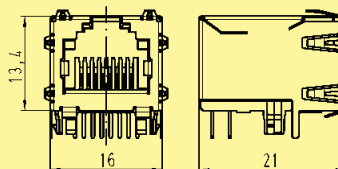


Solder variant, 180° straight


09 35 002 2102

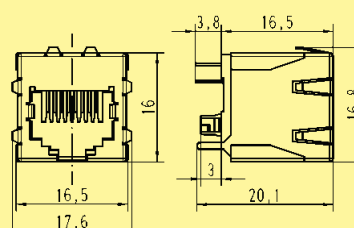

Panel cut out

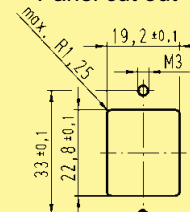

PCB layout

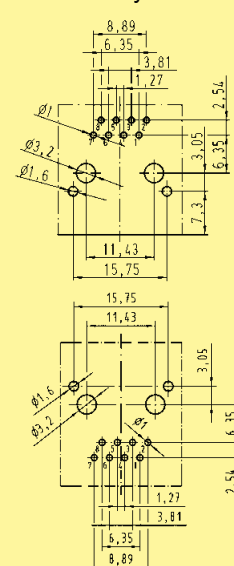

PushPull