


Number of contacts

4/4 +

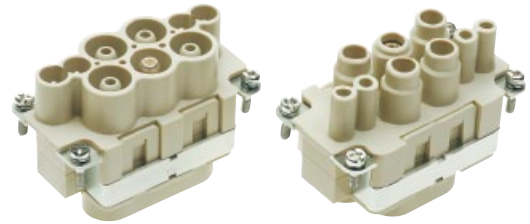

Identification	Part number		Drawing	Dimensions in mm
	Male insert (M)	Female insert (F)		
Han® K 4/4 Axial screw terminal / Cage clamp terminal			<p>1) Distance for contact max. 21 mm</p>	
finger safe 6 ... 16 mm <sup>2</sup>	<b>09 38 008 2601</b>	<b>09 38 008 2701</b>		
finger safe 10 ... 22 mm <sup>2</sup>	<b>09 38 008 2602</b>	<b>09 38 008 2702</b>		
not finger safe 6 ... 16 mm <sup>2</sup>	<b>09 38 008 2611</b>			
not finger safe 10 ... 22 mm <sup>2</sup>	<b>09 38 008 2612</b>			

Identification	Part number	Drawing	Dimensions in mm
Hex key SW 2.5 for axial setscrew			
adapter 1/4"	<b>09 99 000 0375</b>		

