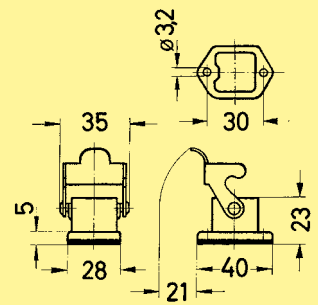
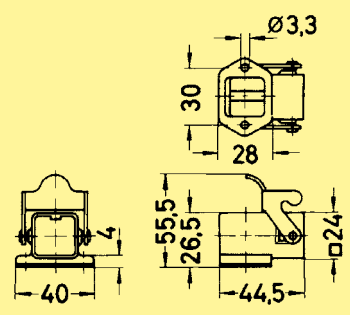
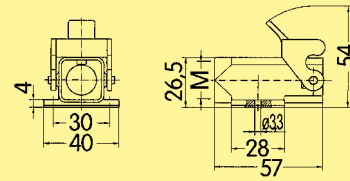
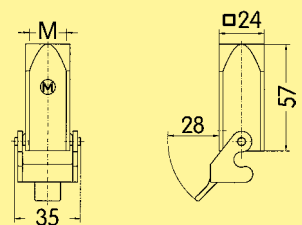
 
 
 


Plastic hoods/housings for industrial applications / 1 lever locking system

Identification	Part number	Cable entry metric	Drawing	Dimensions in mm
Housings, bulkhead mounting	light grey <b>09 20 003 0320</b> black <b>09 20 003 0327</b>			
	light grey <b>09 20 003 0820</b> black 09 20 003 0827			
Housings, surface mounting top entry	light grey <b>19 20 003 0220</b> black 19 20 003 0227	1 x 20 1 x 20		
Hoods, cable to cable top entry	light grey <b>19 20 003 0720</b> black 19 20 003 0727	1 x 20 1 x 20		
Protection covers	light grey 09 20 003 5407 <sup>1)</sup> light grey 09 20 003 5408 <sup>1)2)</sup>			
Protection cover with lanyard	light grey <b>09 20 003 5445<sup>2)</sup></b> light grey 09 20 003 5446 <sup>3)</sup> black 09 20 003 5449 <sup>2)</sup> black 09 20 003 5450 <sup>3)</sup>			
Protection covers for hoods cable to cable	light grey 09 20 003 5447 <sup>2)</sup> light grey 09 20 003 5448 <sup>3)</sup>			

Han Hoods Housings

<sup>1)</sup> for metal housings and cable to cable hoods also <sup>3)</sup> for mounted male insert  
<sup>2)</sup> for mounted female insert or for mounted Han-Brid® insert

Stock items in bold type