
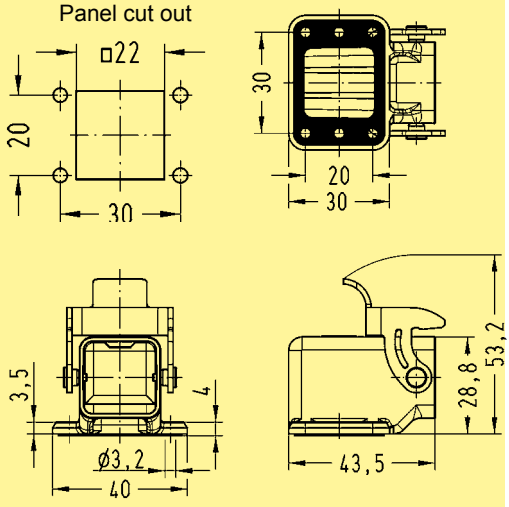

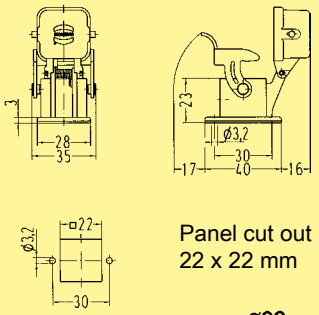

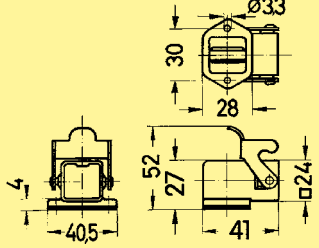

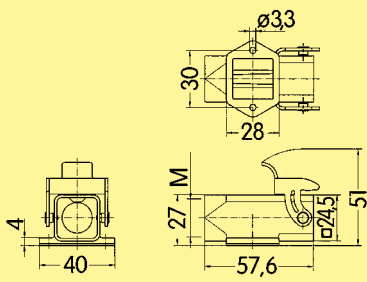

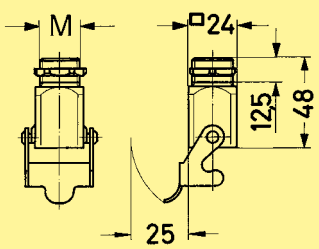


Metal hoods/housings for industrial applications / 1 lever locking system

Identification	Part number	Cable entry metric	Drawing	Dimensions in mm
<p>Angled bulkhead mounted housing</p> 	09 20 003 0810		<p>Panel cut out</p> 	
<p>Housings, bulkhead mounting</p> 	09 20 003 0306		 <p>Panel cut out 22 x 22 mm</p>	
	09 20 003 0801		 <p>Panel cut out 22 x 22 mm</p>	
<p>Housings, surface mounting</p> <p>top entry</p> 	19 20 003 1250	1 x 20	 <p>Panel cut out 22 x 22 mm</p>	
<p>bottom closed</p> <p>19 20 003 1252</p>		1 x 20		
<p>Housings, screw mounting</p> <p>top entry</p> 	19 20 003 1150	1 x 20		

Han Hoods Housings

1) for mounted female insert
2) for mounted male insert

Stock items in bold type