
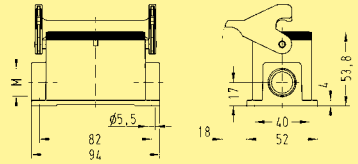

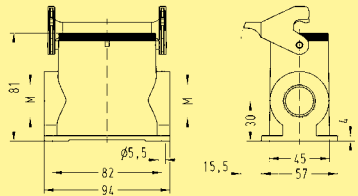

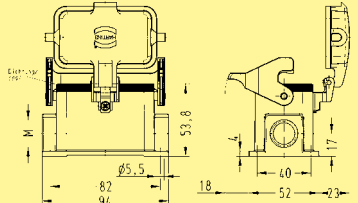

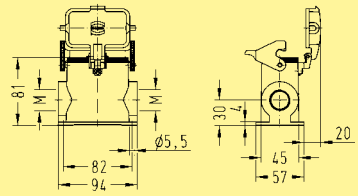

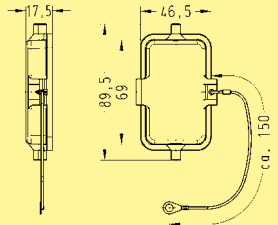


Metal hoods/housings for industrial applications / 1 lever locking system

Identification	Part number		Cable entry metric	Drawing	Dimensions in mm	
	Low construction	High construction				
Housings, surface mounting  side entry		<b>19 30 010 1250</b>	1 x 20 2 x 20		Blind way for one cable entry	
		<b>19 30 010 1290</b>				
side entry			19 30 010 0291 19 30 010 0292	2 x 25 2 x 32		Blind way for one cable entry
side entry		with thermo- plastic cover <b>19 30 010 1255</b>	1 x 20 2 x 20 2 x 20		Blind way for one cable entry	
		with thermo- plastic cover <b>19 30 010 1295</b>				
		with metal cover 19 30 010 2295				
side entry			with thermo- plastic cover 19 30 010 0296 with thermo- plastic cover 19 30 010 0297 with metal cover 19 30 010 7296	2 x 25 2 x 32 2 x 25		Blind way for one cable entry
Protection covers		plastic <b>09 30 010 5412</b>	plastic <b>09 30 010 5412</b>			

Han Hoods  
Housings