
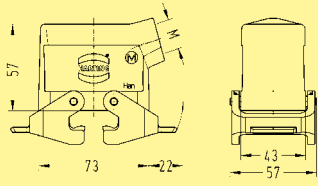
 

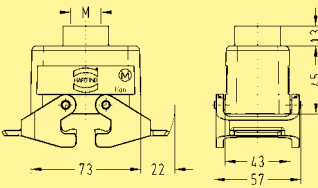
 

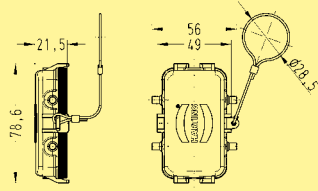
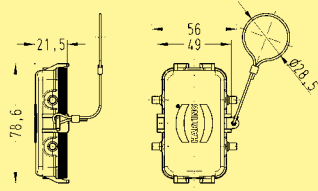

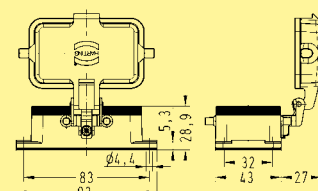
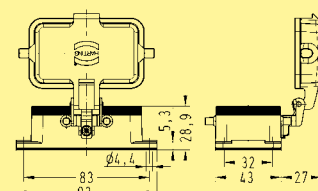
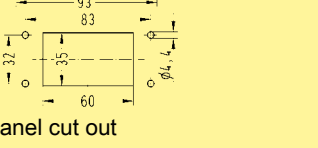


Metal hoods/housings for industrial applications / 2 lever locking system

Identification	Part number		Cable entry metric	Drawing	Dimensions in mm
	Low construction	High construction			
Hoods side entry		19 30 010 1530	1 x 20		
Hoods top entry		19 30 010 1430	1 x 20		
Protection covers		metal 09 30 010 5457	metal 09 30 010 5457		

Metal hoods/housings for industrial applications / 2 lever locking system

Identification	Part number		Cable entry metric	Drawing	Dimensions in mm
	Low construction	High construction			
Housings, bulkhead mounting		with thermo-plastic cover 09 30 010 0302 with metal cover 09 30 010 0317			
				Panel cut out	

Han Hoods
Housings