
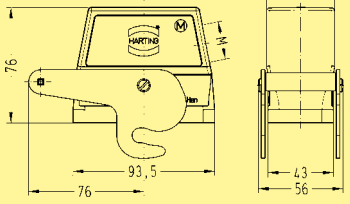

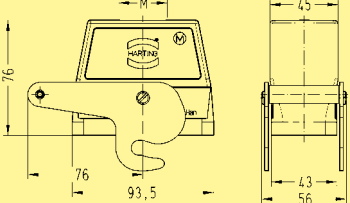

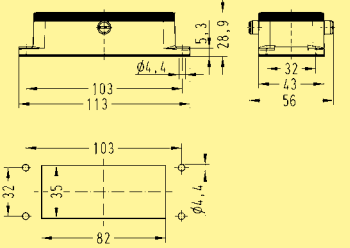

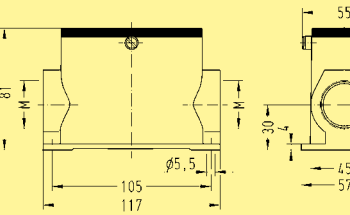


Metal hoods/housings for industrial applications / 1 central locking lever locking system

Identification	Part number	Cable entry metric	Drawing	Dimensions in mm
<p>Hoods</p> <p>side entry</p> 	<p>19 30 016 0586</p> <p>19 30 016 0587</p>	<p>1 x 25</p> <p>1 x 32</p>		<p>76</p> <p>93,5</p> <p>76</p> <p>45</p> <p>43</p> <p>56</p>
<p>Hoods</p> <p>top entry</p> 	<p>19 30 016 0487</p>	<p>1 x 32</p>		<p>76</p> <p>76</p> <p>93,5</p> <p>45</p> <p>43</p> <p>56</p>

Metal hoods/housings for industrial applications / 1 central locking lever locking system

Identification	Part number	Cable entry metric	Drawing	Dimensions in mm
<p>Housings, bulkhead mounting</p> 	<p>09 30 016 0381</p>		 <p>Panel cut out</p>	<p>103</p> <p>113</p> <p>103</p> <p>32</p> <p>35</p> <p>82</p> <p>103</p> <p>5,3</p> <p>28,9</p> <p>32</p> <p>43</p> <p>56</p>
<p>Housings, surface mounting</p> <p>side entry</p> 	<p>19 30 016 0282</p>	<p>2 x 32</p>		<p>81</p> <p>105</p> <p>117</p> <p>55</p> <p>30</p> <p>45</p> <p>57</p> <p>5,5</p>
<p>Han Hoods Housings</p>				