
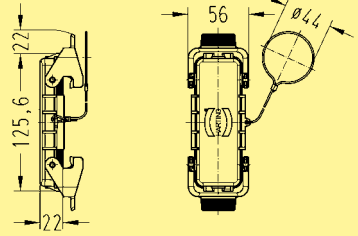
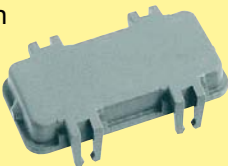
 
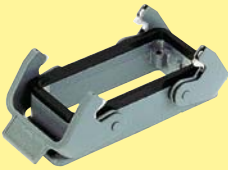
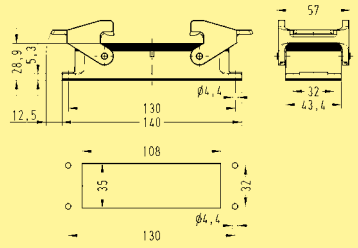

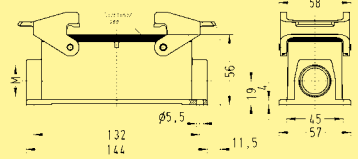

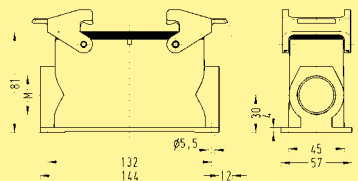


Metal hoods/housings for industrial applications / 2 lever locking system

Identification	Part number	Cable entry	Drawing	Dimensions in mm
Protection covers 	metal 09 30 024 5422	metal 09 30 024 5422		
Dust protection cover 	plastic 09 30 024 5401	plastic 09 30 024 5401		

Metal hoods/housings for industrial applications / 2 lever locking system

Identification	Part number	Cable entry	Drawing	Dimensions in mm
Housings, bulkhead mounting 	09 30 024 0301			Panel cut out
Housings, surface mounting side entry 	19 30 024 1231 19 30 024 1271	1 x 25 2 x 25		Blind way for one cable entry
side entry 	19 30 024 0232 19 30 024 0272 19 30 024 0273	1 x 32 2 x 32 2 x 40		Blind way for one cable entry

Han Hoods Housings