
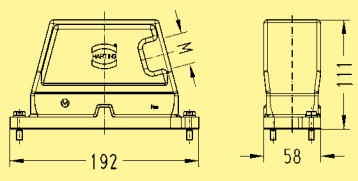

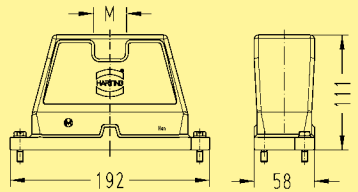

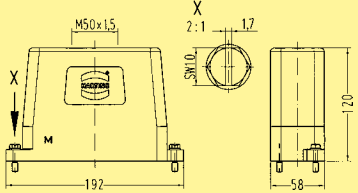

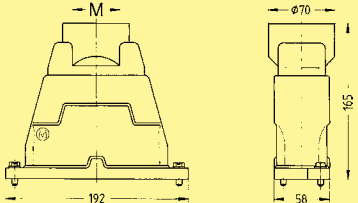

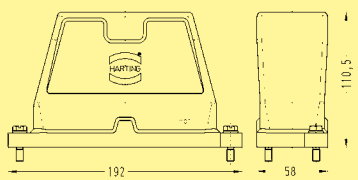


Hoods/Housings for harsh environmental requirements / Screw/toggle locking system

Identification	Part number	Toggle locking	screw	Cable entry metric	Drawing	Dimensions in mm
Hoods side entry 	19 40 024 0503		19 40 024 0512 19 40 024 0513 19 40 024 0514 19 40 024 0537	1 x 40 1 x 32 1 x 40 1 x 50 2 x 32		192 58 111
Hoods top entry 	19 40 024 0402		19 40 024 0412 19 40 024 0413 19 40 024 0414 19 40 024 0431 19 40 024 0432 19 40 024 0433 19 40 024 0461	1 x 32 1 x 32 1 x 40 1 x 50 2 x 25 2 x 32 2 x 40 3 x 25		192 58 111
top entry 			19 40 024 0419 19 40 024 0467	1 x 50 3 x 32		192 58 170
top entry 	19 40 024 0410		19 40 024 0420	1 x 63 1 x 63		192 58 165 70
Hoods without cable entry 			09 40 024 0811	—		192 58 110,5

Han Hoods
Housings