
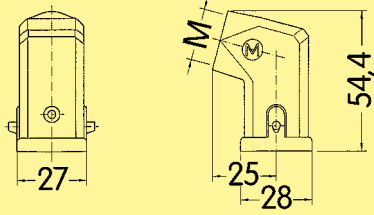

 

 

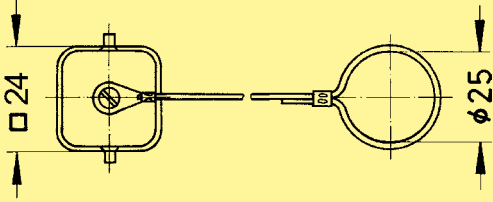


Hoods/Housings made of stainless steel / 1 lever locking system

Identification	Part number	Cable entry metric	Drawing	Dimensions in mm
<p>Hood side entry with glued seal</p> 	<p>19 44 003 1640 19 44 003 1643</p>	<p>20 20</p>		
<p>Hood top entry with glued seal</p> 	<p>19 44 003 1440 19 44 003 1443</p>	<p>1 x 20 1 x 20</p>		
<p>Cable gland</p> 	<p>6 ... 13 mm 19 44 000 5082</p>	<p>1 x 20</p>		
<p>Cover for hoods</p> 	<p>19 44 003 5422²⁾ 19 44 003 5421¹⁾</p>	<p>— —</p>		

Han Hoods
Housings

²⁾ for mounted female insert, ¹⁾ for mounted male insert

Stock items in bold type