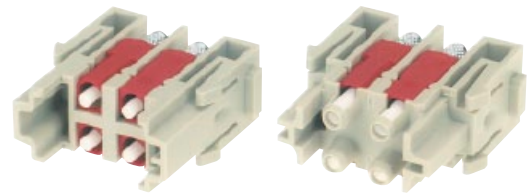

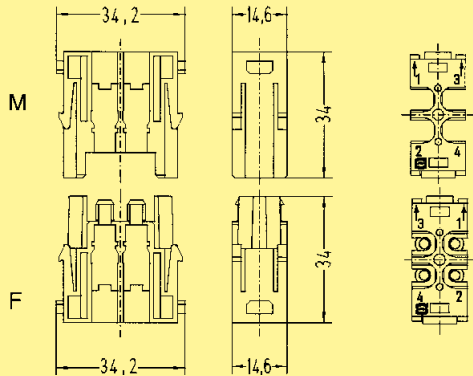

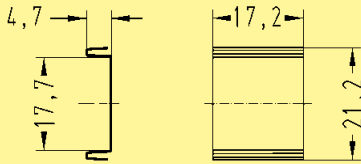



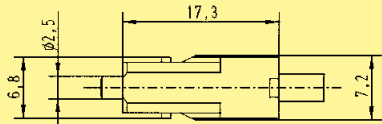
Number of contacts

# 4



Identification	Part number		Drawing	Dimensions in mm
	Male insert (M)	Female insert (F)		
<b>SC module</b> Order contacts separately 	<b>09 14 004 4701</b>	<b>09 14 004 4711*</b>	 <p>M</p> <p>F</p> <p>Contact arrangement view from termination side</p>	
<b>Fixing plate</b> 	09 14 000 9965	09 14 000 9965		

Han Modular

Identification	Part number		Drawing	Dimensions in mm
	Male contact	Female contact		
<b>SC contact</b>  for GI fibre 50/125 µm or 62.5/125 µm ceramic ferrule 	<b>20 10 125 5211</b>	<b>20 10 125 5211</b>		
for SI fibre (HCS®) 200/230 µm	20 10 230 5211	20 10 230 5211		
with quick assembly technique for 1 mm POF	<b>20 10 001 5217</b>	<b>20 10 001 5217</b>		
with crimp technique for 1 mm POF	<b>20 10 001 5211</b>	<b>20 10 001 5211</b>		

\* The female inserts are equipped with centering ferrules.  
 4 ferrules are included in delivery range.

Stock items in bold type