


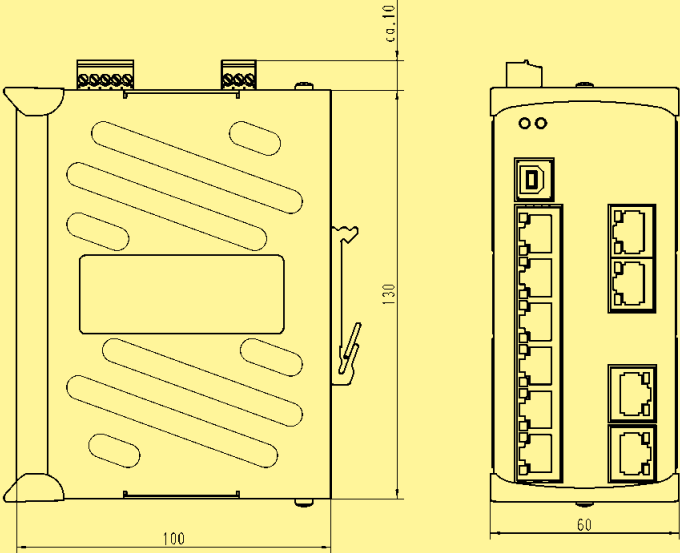

Ethernet Switch
Ha-VIS sCon 3100-AA

10-port Ethernet Switch for mounting onto top-hat mounting rail in control cabinets,
including 2 Gigabit ports and sCon functions, extended temperature range

Unmanaged	IP 30	PROFINET comatible ☒	EtherNet/IP compatible ☐
Number of ports, Copper / Termination	8x 10/100Base-T(X) / RJ45 (Twisted Pair) 2x 10/100/1000-Base-T(X) / RJ45 (Twisted Pair)		
Input voltage / Termination	24 / 48 V DC / 5-pole, pluggable screw contact, for redundant power supply		
Permissible range (min./max.)	9,6 V ... 60 V DC		
Input current	approx. 240 mA (at 24 V DC)		
Alarm signalling contact	Change-over contact, potential-free, 24 V DC / 0.5 A 3-pole pluggable screw contact		
Housing material	metal, powder-coated		
Dimensions (W x H x D)	60 x 132 x 104 mm (including cap, without connectors)		
weight	approx. 0,6 kg		
Working temperature	-40 °C ... +70 °C		
Approvals	UL 508; UL 60 950-1; DNV		
MTBF	670.000 h		

Identification	Part number	Drawing	Dimensions in mm
Ha-VIS sCon 3100-AA Ethernet Switch with 10 RJ45 ports	20 76 110 1001		

sCon 3000