

# HARAX® Circular connector M8



Circular Connectors


Identification Male Part No. Female Drawing Dimensions in mm

## HARAX® M8-XS

straight version, 3-poles  
for 0.1 - 0.14 mm<sup>2</sup>



**21 02 159 1305**

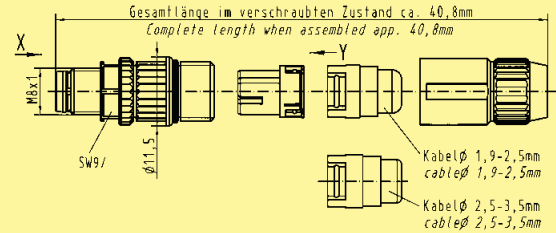


## HARAX® M8-S

straight version, 3-poles  
for 0,14 - 0,34 mm<sup>2</sup>




**21 02 151 1305**

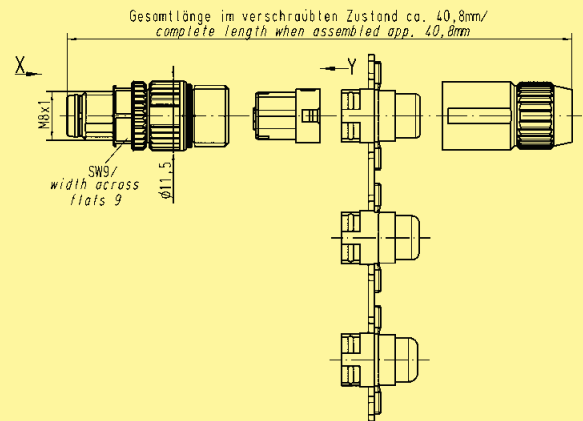

straight version, 4-poles  
for 0,14 - 0,34 mm<sup>2</sup>



**21 02 151 1405**

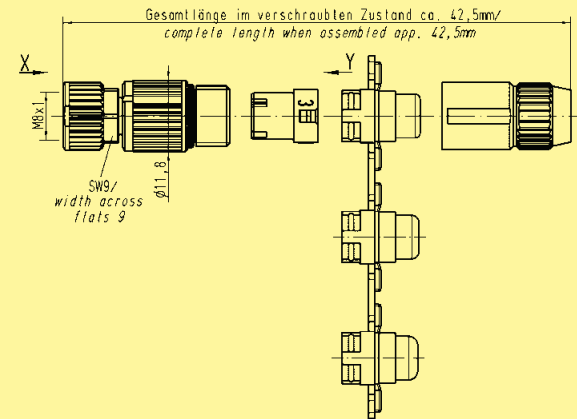

straight version, 3-poles  
for 0,14 - 0,34 mm<sup>2</sup>



**21 02 151 2305**

straight version, 4-poles  
for 0,14 - 0,34 mm<sup>2</sup>



**21 02 151 2405**

View mating side:  
3-poles, male version



View mating side:  
4-poles, male version

