


# Circular connector M12 shielded, A-coded acc. to IEC 61076-2-101

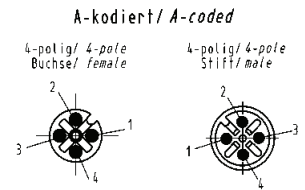

Identification	Male	Part No.	Female	Drawing	Dimensions in mm
----------------	------	----------	--------	---------	------------------

## HARAX® M12-L, screened version

4-poles, A-coded  
0.14 - 0.34 mm<sup>2</sup> / AWG 26 - 22




**21 03 221 1405**

4-poles, A-coded  
0.14 - 0.34 mm<sup>2</sup> / AWG 26 - 22



**21 03 221 2405**

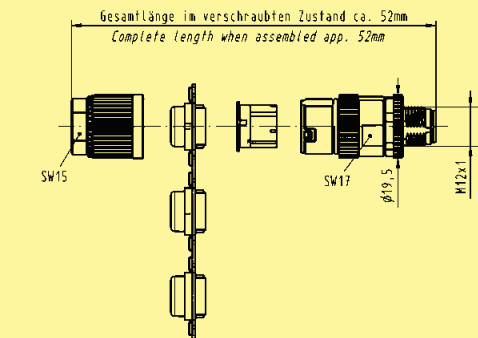

## HARAX® panel feed-through

4-poles, A-coded  
0.14 - 0.34 mm<sup>2</sup> / AWG 26 - 22




**21 03 321 1425**

4-poles, A-coded  
0.14 - 0.34 mm<sup>2</sup> / AWG 26 - 22



**21 03 321 2425**

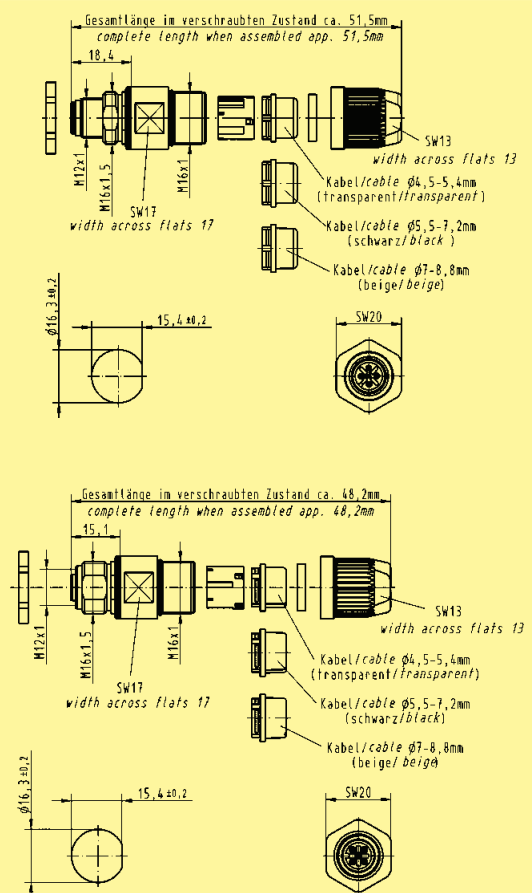

Stock items in bold type