

 
 
# Circular connector M12 shielded, D-coded acc. to IEC 61076-2-101



D-kodiert / D-coded

4-polig / 4-pole  
Buchse / female

4-polig / 4-pole  
Stift / male



Identification	Male	Part No.	Female	Drawing	Dimensions in mm
----------------	------	----------	--------	---------	------------------

## HARAX® M12-L, screened version

4-poles, D-coded,  
0.14 - 0.34 mm<sup>2</sup>, AWG 26-22  
0.34 - 0.5 mm<sup>2</sup>, AWG 22-20



4-poles, D-coded,  
0.14 - 0.34 mm<sup>2</sup>, AWG 26-22  
0.34 - 0.5 mm<sup>2</sup>, AWG 22-20



**21 03 281 1405**  
**21 03 282 1405**

**21 03 281 2405**  
**21 03 282 2405**

## HARAX® panel feed-through

D-coded  
0.14 - 0.34 mm<sup>2</sup>, AWG 26 - 22




D-coded  
0.14 - 0.34 mm<sup>2</sup>, AWG 26 - 22



**21 03 381 1425**

**21 03 381 2425**

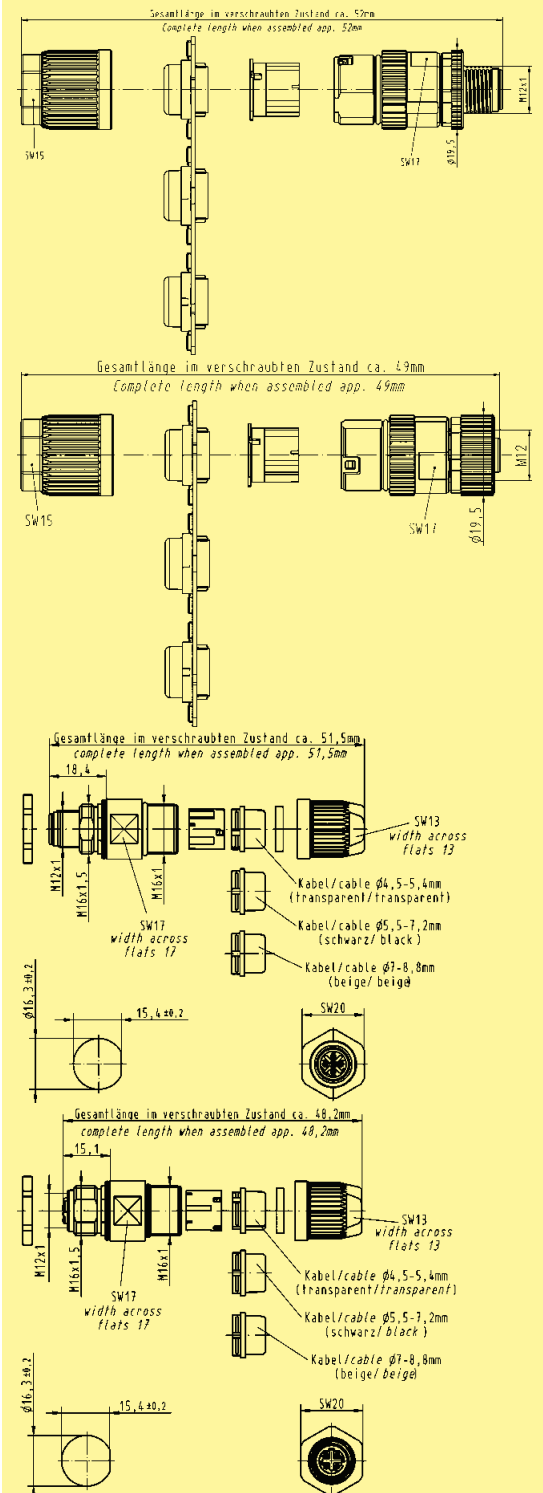

Circular Connectors