

Plug sockets

Part number

Depiction

Germany (VDE)  
with LED display  
screw terminals for max. 6 mm<sup>2</sup>  
connection at the rear

**39 50 001 0001**



Germany (VDE)  
for assembly in front of main switch  
flourescent colour yellow (RAL 1016)  
without LED display  
screw terminals for max. 6 mm<sup>2</sup>  
connection at the rear

**39 50 001 0002**

USA / Euro  
finger protected  
screw terminals for max. AWG 14 (2.5 mm<sup>2</sup>)

**39 50 001 0010**




USA (NEMA5-15) / Japan  
finger protected  
screw terminals for max. AWG 14 (2.5 mm<sup>2</sup>)

**39 50 001 0004**

France (UTE)  
with LED display  
screw terminals for max. 6 mm<sup>2</sup>  
connection at the rear

**39 50 001 0005**

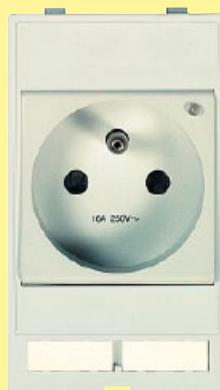

Great Britain (BS)  
finger protected  
screw terminals for max. 4 mm<sup>2</sup>

**39 50 001 0006**



Han-Port