

Product information

ASB 4/LED 5-4-328/... M - ASB 4/LED 5-4-328/10 M

Industrial Connecting Solutions:I/O Modules:Passive distributors:M12 Passive Distributors:fixed control cable:with LED:1 signal/socket (3+PE):ASB 4/LED 5-4-328/... M
http://e-catalog.hirschmann.com/link/57078-24228-255441-199791-200292-204934-204940-204946-205054/en/ASB_04_LED_5_4_328_10/ulistate


Name	ASB 4/LED 5-4-328/... M
	 <p>Image similar Abb. ähnlich</p>
	Actuator/sensor distribution box, 4-port version, with LED operation and function indicators, combined FIXCON-/M12 socket, 4-pole, 1 signal per socket, earth connection, fixed connection cable, PUR jacket, halogen-free, black, 10 meter.
Delivery informations	
Availability	available
Product description	
Type	ASB 4/LED 5-4-328/10 M
Order No.	60643
Description	Actuator/sensor distribution box, 4-port version, with LED operation and function indicators, combined FIXCON-/M12 socket, 4-pole, 1 signal per socket, earth connection, fixed connection cable, PUR jacket, halogen-free, black, 10 meter.
Number of contacts	4 (M12)
Version	4 ports
Color of housing	orange
Product characteristics	Vibration resistance, Oil resistance, Drag chains suitable
Classification	
Belden brand	Lumberg-Automation
Mechanical data	
Thread	M12
LED display present	✓
Environmental conditions	
Environmental temperature	-15 °C ... 80 °C
Degree of protection (IP), mounted	IP67
Pollution degree	3
Materials	
Housing material / Molded body	TPU, self-extinguishing
Contact bearer material	PA-GF, self-extinguishing
Contact material	CuZn (M12)
Contact material - Surface refinement	pre-nickel and 0.8 microns gold-plated
Knurled screw / nut material	CuZn, nickel-plated
Sealing material	FKM
Electrical data	
Contact resistance	≤ 5 mΩ
Rated current In	4 A per socket / 12 A max. at 40°C
Nominal voltage	10 - 30 V DC
Rated voltage	32 V
Insulation resistance	> 1 GΩ
Approvals	
Approvals	cURus
Cable	
Cable length	10 m
Cable number	328
Cable description	Control cable
Color of jacket	black
Material of outer jacket	PUR
Outer diameter of the cable	6.8 mm

Industrial Connecting Solutions:I/O Modules:Passive distributors:M12 Passive Distributors:fixed control cable:with LED:1 signal/socket (3+PE):ASB 4/LED 5-4-328/... M

http://e-catalog.hirschmann.com/link/57078-24228-255441-199791-200292-204934-204940-204946-205054/en/ASB_04_LED_5_4_328_10/uistate

Number of conductors	7
Cable design	4 x 0.34 mm ² + 3 x 0.75 mm ²
Flame resistant according to standard	IEC 60332-2, CSA FT-2
Scope of delivery and accessories	
Scope of delivery	ZVK: 2 dust covers for unused sockets ZBS: 10 attachable labels

Picture

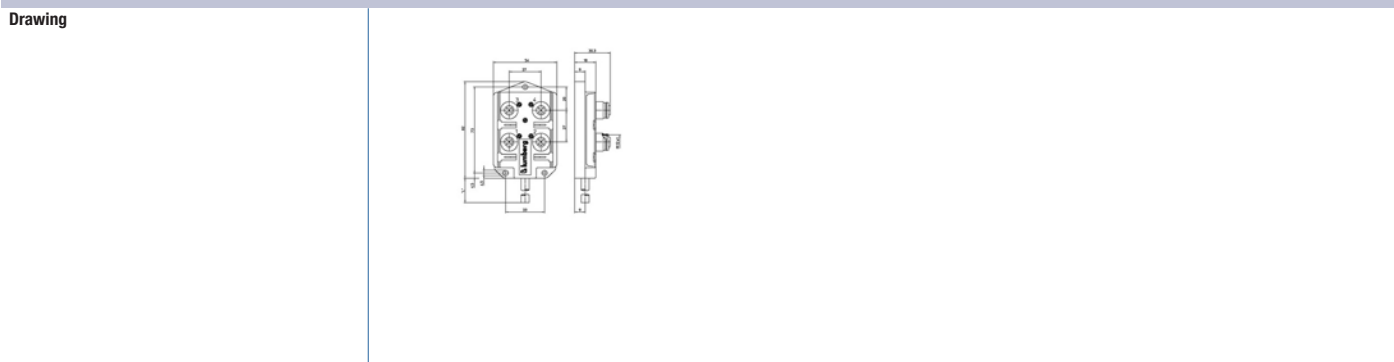

Belden Deutschland GmbH
 Im Gewerbepark 2
 58579 Schalksmühle
 Germany
 Phone: +49 7127/14-1806
 E-Mail: icos-sales@belden.com

The information published in the websites has been compiled as carefully as possible. It is subject to alteration without notice in technical as well as in price-related/commercial respect. The complete information and data were available on user documentation. Mandatory information can only be obtained by a concrete query.