

## M12-Splitters/T-Connectors


ASBS 2 M12-S2326 | ASBS 2 M12-S2325



### M12 Male to 2xM12 Female

Splitter/T-connector, two way, 4-poles with one M12 male connector and two M12 female connectors.


### ASBS 2 M12-S2326

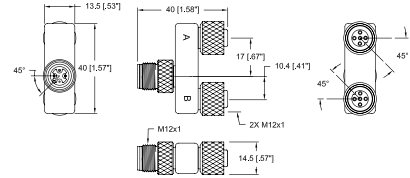

### M12 Male to 2xM12 Female

Splitter/T-connector, two way, 5-poles with one M12 male connector and two M12 female connectors.


### ASBS 2 M12-S2325

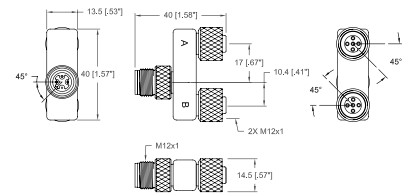


## Pin Assignments

### Face Views

 ASBS 2 M12-S2326




ASBS 2 M12-S2325

 


### Wiring Diagrams

ASBS 2 M12-S2326

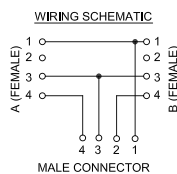

ASBS 2 M12-S2325

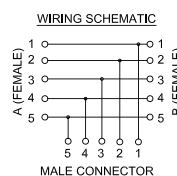



Be Certain with Belden

**M12-Splitters/T-Connectors**

ASBS 2 M12-S2326 | ASBS 2 M12-S2325

**Technical Data**

**Environmental**

Degree of protection IP 67 / NEMA 6P  
 Operating temperature range -15°C (+5°F) / +90°C (+194°F)

**Mechanical**

Molded body PUR, black  
 Insert PUR, black  
 Contact Brass, gold over nickel plated  
 Coupling nut Brass, nickel-plated  
 O-ring FKM

**Electrical**

Contact resistance ≤ 5 mΩ  
 Current rating 4 A  
 Voltage rating 250 V

Splitters and Adapters

| Part Number      | Pins | Characteristics   |
|------------------|------|---|
| ASBS 2 M12-S2326 | 4    |  |
| ASBS 2 M12-S2325 | 5    |  |