



DeviceNet Field Attachable Connectors, 7/8"


0936 DMC 301 | 0936 DMC 303



5-Pole, Male

DeviceNet, 5-pole, male field attachable 7/8" connector with screw terminal connection, cable outlet suitable for THIN and THICK DeviceNet cable.

0936 DMC 301 | 0936 DMC 303

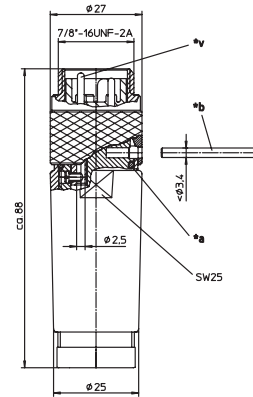


0936 DFC 301 | 0936 DFC 303



5-Pole, Female

DeviceNet, 5-pole, female field attachable 7/8" connector with screw terminal connection, cable outlet suitable for THIN and THICK DeviceNet cable.


0936 DFC 301 | 0936 DFC 303

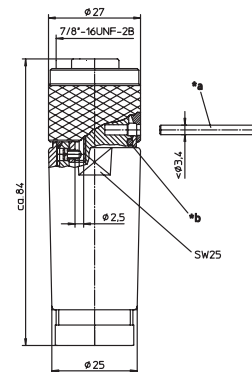

Pin Assignments

Face Views / 7/8"

 5 pole





Be Certain with Belden

DeviceNet Field Attachable Connectors, M12

0936 DMC 301 | 0936 DMC 303 | 0936 DFC 301 | 0936 DFC 303

Technical Data

Environmental

Degree of protection IP 67 / NEMA 6P
 Operating temperature range -40°C (-40°F) / +90°C (+194°F)

Materials

Housing / Molded body PA
 Insert TPU, self-extinguishing
 Contact CuZn, pre-nickel and 0.8 microns gold-plated
 Coupling nut Aluminum, black anodized
 O-ring NBR

Mechanical

Mode of connection Screw terminals
 Connectable conductor max. 1.5 mm²

Electrical

Current rating 8 A
 Voltage rating 250 V

| Part Number | | Pins | Cable Type | Characteristics |
|--------------|--------------|------|------------|-----------------|
| 0936 DMC 301 | | 5 | Thin | UL |
| 0936 DMC 303 | | 5 | Thick | UL |
| | 0936 DFC 301 | 5 | Thin | UL |
| | 0936 DFC 303 | 5 | Thick | UL |