

Mini, 1 1/8"-Round-Plug Connector, Double-Ended Cordsets, US Color Code


RSRK 901M...1201M



9-, 10-, and 12-Poles

Mini, 1 1/8" double-ended cordsets, male straight to female straight connector, 9-, 10-, and 12-poles with molded cable, US color code.


RSRK

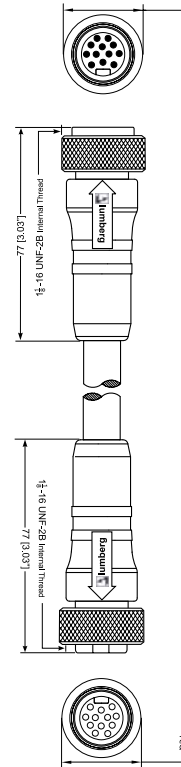

Pin Assignments


Mini, 1 1/8" - Male / Female

 9 poles




- 1 = orange
- 2 = blue
- 3 = red/black
- 4 = green/black
- 5 = white
- 6 = red
- 7 = green
- 8 = white/black
- 9 = black

 10 poles



- 1 = orange
- 2 = blue
- 3 = white/black
- 4 = red/black
- 5 = green/black
- 6 = orange/black
- 7 = red
- 8 = green
- 9 = black
- 10 = white

 12 poles



- 1 = orange
- 2 = blue
- 3 = white/black
- 4 = red/black
- 5 = green/black
- 6 = orange/black
- 7 = blue/black
- 8 = black/white
- 9 = green
- 10 = red
- 11 = white
- 12 = black



Be Certain with Belden

Mini, 1 1/8"-Round-Plug Connector, Double-Ended Cordsets, US Color Code RSRK 901M...1201M

Technical Data

Environmental

Degree of protection IP 67 / NEMA 6P
Operating temperature range -40°C (-40°F) / +90°C (194°F)

Mechanical

Housing / Molded body TPU, yellow
Insert TPU, yellow
Contact CuZn, gold over silver plated
Coupling nut Aluminum, anodized black

Electrical

Current rating 9-10 pole: 7 A
12 pole: 5 A
Voltage rating 623, 699, 724: 600 V
651, 652, 654: 300 V

Cable Specifications - US Color Code

Cable No.	Outer Jacket	Gauge	Jacket Color	OD	Temperature Rating	Agency Approvals
623	PVC	16AWG	Yellow	.660" (16.8 mm)	-40°C (-40°F) to +90°C (194°F)	UL: STOW / CSA: AWM I/II A/B
651	PUR	18AWG	Yellow	.313" (8.0 mm)	-40°C (-40°F) to +80°C (176°F)	UL: AWM 20233 / CSA: AWM I/II A/B
699	PVC	16AWG	Yellow	.660" (16.8 mm)	-40°C (-40°F) to +90°C (194°F)	UL: STOW / CSA: AWM I/II A/B
652	PUR	18AWG	Yellow	.340" (8.6 mm)	-40°C (-40°F) to +80°C (176°F)	UL: AWM 20233 / CSA: AWM I/II A/B
724	TPE	16AWG	Yellow	.690" (17.5 mm)	-50°C (-58°F) to +90°C (194°F)	UL: SE00W / CSA: STOW
654	PUR	18AWG	Yellow	.354" (9.0 mm)	-40°C (-40°F) to +80°C (176°F)	UL: AWM 20233 / CSA: AWM I/II A/B

Part Number	Pins	Outer Jacket	Standard Cable Lengths	Characteristics
RSRK 901M-623/...F	9	PVC	6 F / 12 F / 15 F / 20 F / 30 F	  
RSRK 901M-651/...F				
RSRK 1001M-699/...F	10	PVC	6 F / 12 F / 15 F / 20 F / 30 F	  
RSRK 1001M-652/...F				
RSRK 1201M-724/...F	12	TPE	6 F / 12 F / 15 F / 20 F / 30 F	  
RSRK 1201M-654/...F				