

Mini Actuator/Sensor Distribution Boxes


ZLU 4-30 | ZLU 4L 30 | ZLU 4-50



4-Ports


Distribution box, 4-ports with or without lamp indicators, side-entry, 7/8" sockets, 3- and 5-poles with integrated on-board quick-disconnect.

ZLU 4-30

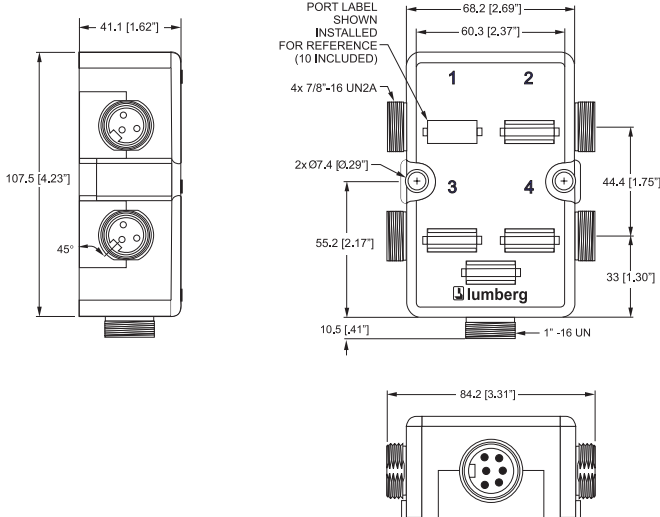


Wiring Diagrams


ZLU 4-30

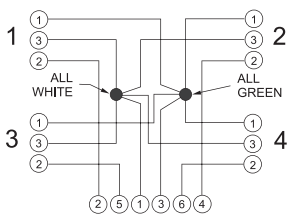

ZLU 4-50

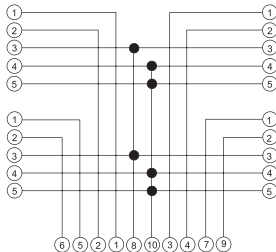


ZLU 4L-30

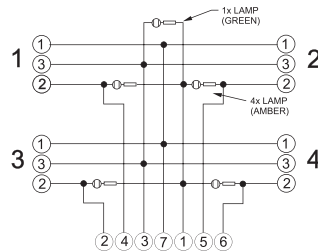


Pin Assignments

7/8" (

 3 poles (ZLU 4-30)




5 poles (ZLU 4-50)

 


7/8" (Control Connection)

 6 poles (ZLU 4-30)




1" (Control Connection)

 7 poles (ZLU 4L-30)



1 1/8" (Control Connection)

10 poles (ZLU 4-50)

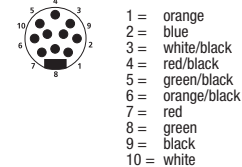



Mini Actuator/Sensor Distribution Boxes

ZLU 4-30 | ZLU 4L 30 | ZLU 4-50

Technical Data

Environmental

Degree of protection
Operating temperature range

IP 67 / NEMA 6P
-25°C (-13°F) / +90°C (+194°F)

Mechanical

Housing
I/O port shell
Control port shell
Contacts
Insert

Polyester, glass filled, yellow TPE, black
Zinc alloy, e-coated black
Aluminum, anodized black
CuZn, gold plated
PUR, yellow




Electrical

Current rating




8 A per port
12 A max. per box
600 V

Voltage rating
Technical Data

ZLU 4L-30

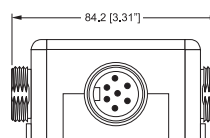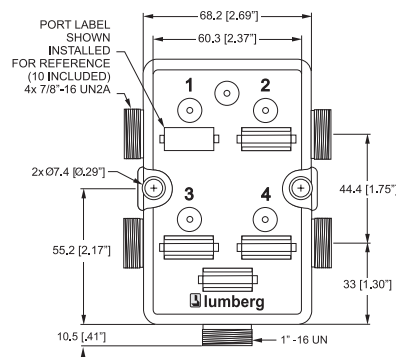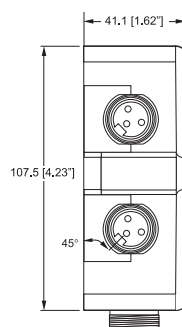

ZLU 4-50

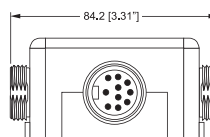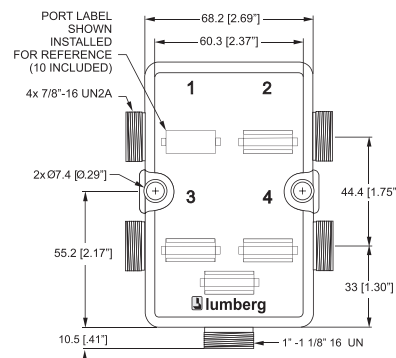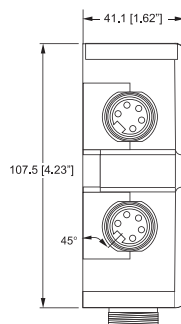

Part Number	Ports	Lamp Indicators	Mating Control Cables	Characteristics
ZLU 4-30	4		RSRK 601A-697/...F	 
ZLU 4L-30	4	Lamps	RSRK 701M-622/...F	 
ZLU 4-50	4		RSRK 1001M-699/...F	 