






H-15 Straight Blade Plugs & Connectors

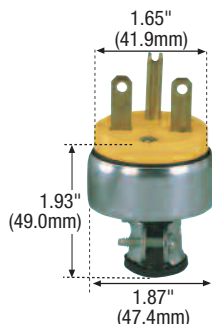

2866

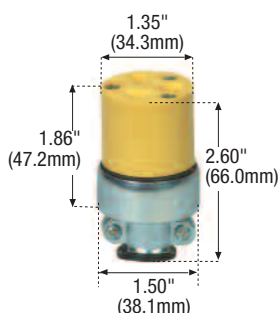

2229

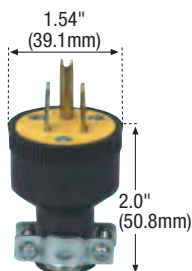

1709



222

TESTING & CODE COMPLIANCE

- Listed to UL 498 (file no. E15012).
- CSA Certified to C22.2 no. 42 (file no. 2081 (6221-02)).
- NOM Certified, except as noted.

MATERIAL CHARACTERISTICS

PVC and Thermoplastic Rubber.
Environmental:
Meets flammability requirements per UL 94, VO rated except 229.
Temperature Rating:
-20°C to 60°C., except #229:
-20°C to 70°C.

Commercial Specification Grade Plugs and Connectors

2-Pole, 3-Wire Grounding
NEMA 5-15, 15A 125V
NEMA 6-15, 15A 250V
NEMA 5-20, 20A 125V
NEMA 6-20, 20A 250V
NEMA 7-15, 15A 277V

Vinyl Armored and Rubber Plugs

FEATURES

- Solid brass plug blades are firmly embedded in body.
- Terminal screw clamps are designed to contain wire and prevent binding.
- Terminal screws backed out – ready for wiring.
- Terminals in individual chambers to positively insulate conductors.
- Armored housing automatically grounded.
- Combination slot/Phillips head mounting and terminal screws ease installation with power screwdrivers (Slot/Robertson screws in Canada where available).

Vinyl Armored Plugs

Rating		NEMA	Description	Cord Diameter	Color	Catalog No.	
A	V/AC					Plug	Connector
15	125	5-15	Straight	0.25-0.625" (6.35-15.87mm)	Yellow	2867	2887
15	250	6-15	Straight	0.25-.0625" (6.35-15.87mm)	Yellow	2866	2227
15	277	7-15	Straight	0.25-0.625" (6.35-15.87mm)	Yellow	2839**	—
20	125	5-20	Straight	0.25-0.625" (6.35-15.87mm)	Yellow	2809	2228
20	250	6-20	Straight	0.25-0.625" (6.35-15.87mm)	Yellow	3809	2229

**Not NOM

Thermoplastic Rubber Plugs

Rating		NEMA	Description	Cord Diameter	Color	Catalog No.	
A	V/AC					Plug	Connector
15	125	5-15	Straight	0.25-0.60" (6.35-15.24mm)	Black	1709	222**
15	250	6-15	Straight	0.25-0.60" (6.35-15.24mm)	Black	1711	229††
20	250	6-20	Straight	0.25-0.60" (6.35-15.24mm)	Black	1703	—

** Not NOM

†† Not NOM or CSA



5-15P



5-15R



7-15P



5-20P



5-20R



6-20P



6-20R