


Wallplates

Decorator Screwless, Mid-Size and Standard

Contemporary design, sleek elegant lines, and a multitude of material, size and color choices make the Decorator Style an easy choice.

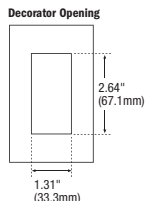

PJS26W

Gang	Description	Cat. No.	Color
Mid-Size			
1-Gang	Screwless	☐ PJS26__	A, B, BK, GY, LA, V, W
2-Gang	Screwless	☐ PJS262__	A, B, BK, GY, LA, V, W
3-Gang	Screwless	☐ PJS263__	A, BK, LA, V, W
4-Gang	Screwless	☐ PJS264__	A, BK, LA, V, W
5-Gang	Screwless	☐ PJS265__	A, BK, LA, V, W
6-Gang	Screwless	☐ PJS266__	A, BK, LA, V, W
1-Gang	Polycarbonate	☐ PJ26__	A, B, BK, BL, GY, LA, RD, V, W
2-Gang	Polycarbonate	☐ PJ262__	A, B, BK, BL, GY, LA, RN, RD, V, W
3-Gang	Polycarbonate	☐ PJ263__	A, B, BK, GY, LA, V, W
4-Gang	Polycarbonate	☐ PJ264__	A, B, BK, GY, LA, V, W
5-Gang	Polycarbonate	☐ PJ265__	A, B, BK, GY, LA, V, W
6-Gang	Polycarbonate	☐ PJ266__	A, B, BK, GY, LA, V, W
1-Gang	Thermoset	☐ 2051__	A, B, LA, V, W
2-Gang	Thermoset	☐ 2052__	A, LA, V, W
3-Gang	Thermoset	☐ 2063__	A, LA, V, W
4-Gang	Thermoset	☐ 2064__	A, LA, V, W
1-Gang	Stainless Steel	☐ 93934__	SS
2-Gang	Stainless Steel	☐ 93935__	SS
3-Gang	Stainless Steel	☐ 93936__	SS
Standard-Size			
1-Gang	Nylon	☐ 5151__	A, B, BK, BL, GY, LA, RD, V, W
2-Gang	Nylon	☐ 5152__	A, B, BK, GY, LA, V, W
1-Gang	Thermoset	☐ 2151__	A, B, BK, GY, LA, V, W
2-Gang	Thermoset	☐ 2152__	A, B, BK, GY, LA, V, W
3-Gang	Thermoset	☐ 2163__	A, B, GY, LA, V, W
4-Gang	Thermoset	☐ 2164__	A, B, LA, V, W
5-Gang	Thermoset	☐ 2165__	A, B, LA, V, W
6-Gang	Thermoset	☐ 2166__	A, B, LA, V, W
1-Gang	Stainless Steel	☐ 93401__	SS
2-Gang	Stainless Steel	☐ 93402__	SS
3-Gang	Stainless Steel	☐ 93403__	SS
4-Gang	Stainless Steel	☐ 93404__	SS
5-Gang	Stainless Steel	☐ 93405__	SS
6-Gang	Stainless Steel	☐ 93406__	SS
1-Gang	Brass	☐ 94401__	Brass
2-Gang	Brass	☐ 94401__	Brass

For ordering wallplates, include Cat. No. followed by the color code: A (Almond), B (Brown), BK (Black), BL (Blue), GY (Gray), LA (Light Almond), RD (Red), RN (Orange), SS (Stainless Steel), V (Ivory), W (White)

Regulatory

- UL 514D and cUL Listed, UL file #E33216
- Meets Federal Specification WP-455. Meets all CSA requirements, C22.2 no. 42.1
- Meets flammability requirements per UL 94, V2 rated

Screwless

- Screwless wallplates appear to float freely on the surface of the wall
- Mounting plate attaches to the wiring device and the wallplate is simply pressed into place for an easy and fast installation.
- Mid-sized to cover wall imperfections and large wallboard openings
- Virtually unbreakable polycarbonate construction

Thermoplastic


- Exclusive time-saving Screw-Catch™ feature holds mounting screws captive, simplifying installation
- Nylon wallplates are flush-fitting and warp resistant
- Polycarbonate wallplates are virtually unbreakable, with high structural rigidity, long-term form retention, and superior impact resistance
- Temperature rating: -40°C to 70°C

Traditional Screwless, Mid-Size and Standard

The Traditional Style offers timeless styling for traditional décor and a wide selection of choices to meet a range of applications.



PJS1W

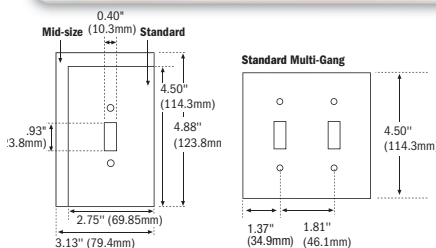

Gang	Description	Cat. No.	Color
Mid-Size			
1-Gang	Screwless	□ PJS1__	A, B, BK, LA, V, W
2-Gang	Screwless	□ PJS2__	A, B, BK, LA, V, W
3-Gang	Screwless	□ PJS3__	A, LA, V, W
4-Gang	Screwless	□ PJS4__	A, LA, V, W
Standard-Size			
1-Gang	Polycarbonate	□ PJ1__	A, B, BK, BL, GY, LA, RD, V, W
2-Gang	Polycarbonate	□ PJ2__	A, B, BK, BL, GY, LA, RD, V, W
3-Gang	Polycarbonate	□ PJ3__	A, B, BK, BL, GY, LA, RD, V, W
4-Gang	Polycarbonate	□ PJ4__	A, B, BK, GY, LA, V, W
5-Gang	Polycarbonate	□ PJ5__	A, B, BK, GY, LA, V, W
6-Gang	Polycarbonate	□ PJ6__	A, B, BK, GY, LA, V, W
1-Gang	Thermoset	□ 2034__	A, B, LA, V, W
2-Gang	Thermoset	□ 2039__	A, B, LA, V, W
3-Gang	Thermoset	□ 2041__	A, B, LA, V, W
4-Gang	Thermoset	□ 2054__	A, LA, V, W
1-Gang	Stainless Steel	□ 93971__	SS
2-Gang	Stainless Steel	□ 93972__	SS
3-Gang	Stainless Steel	□ 93973__	SS
Standard-Size			
1-Gang	Nylon	□ 5134__	A, B, BK, GY, LA, RD, V, W
2-Gang	Nylon	□ 5139__	A, B, BK, GY, LA, RD, V, W
3-Gang	Nylon	□ 5141__	A, B, BK, GY, LA, V, W
4-Gang	Nylon	□ 5154__	A, B, BK, GY, LA, V, W
1-Gang	Thermoset	□ 2134__	A, B, BK, GY, LA, V, W
2-Gang	Thermoset	□ 2139__	A, B, BK, GY, LA, V, W
3-Gang	Thermoset	□ 2141__	A, B, GY, LA, V, W
4-Gang	Thermoset	□ 2154__	A, B, LA, V, W
5-Gang	Thermoset	□ 2155__	A, B, LA, V, W
6-Gang	Thermoset	□ 2156__	A, B, LA, V, W
1-Gang	Stainless Steel	□ 93071__	SS
2-Gang	Stainless Steel	□ 93072__	SS
3-Gang	Stainless Steel	□ 93073__	SS
4-Gang	Stainless Steel	□ 93074__	SS
5-Gang	Stainless Steel	□ 93075__	SS
6-Gang	Stainless Steel	□ 93076__	SS
1-Gang	Brass	□ 94071__	Brass
2-Gang	Brass	□ 94072__	Brass
3-Gang	Brass	□ 94073__	Brass

For ordering wallplates, include Cat. No. followed by the color code: A (Almond), B (Brown), BK (Black), BL (Blue), GY (Gray), LA (Light Almond), RD (Red), RN (Orange), SS (Stainless Steel), V (Ivory), W (White)

Thermoset

- Extensive line of non-flammable thermoset plates provides flush-fitting, warp-resistant performance
- Temperature rating: -40°C to 65°C

Stainless Steel

- Superior non-corrosive and non-magnetic properties for applications needing protection from those elements
- Horizontally satin-brushed surface finish resists finger prints

Solid Brass

- Strong, corrosion-resistant and coated with transparent lacquer to resist premature oxidation
- Horizontally satin-brushed surface finish resists finger prints