



Product information N6R 3 LED 24 DB

Industrial Connecting Solutions: Circular Connectors: MIL, DIN, Universal Connectors: DIN 43651 Connectors (NR series): Accessories NR-series: N6R 3 LED 24 DB

<http://www.e-catalog.beldensolutions.com/link/57078-24228-256281-256284-24367-24374-36315/en/conf/ui/state>

Name N6R 3 LED 24 DB



LED insert with 3 LEDs (green, yellow, red) to indicate operation conditions

Delivery informations

Availability available

Product description

Description LED insert with 3 LEDs (green, yellow, red) to indicate operation conditions

Type N6R 3 LED 24 DB

Order No. 831 618-001

Technical data

Rated voltage DC 24 V

Rated current 10 A

Contact resistance $\leq 5 \text{ m}\Omega$

Type of termination plug in

Environmental conditions

Temperature range $-40 \text{ }^\circ\text{C}$ to $+90 \text{ }^\circ\text{C}$

Packing unit


Packaging unit 10 pieces

Scope of delivery and accessories

Accessories to order separately can be plugged into N6R FF S 11

Picture

Drawing

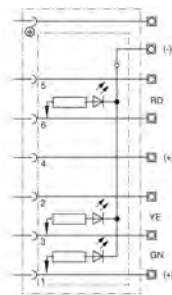

Belden Deutschland GmbH

Im Gewerbepark 2

58579 Schalksmühle

Germany

Phone: +49 7127/14-1806

E-Mail: icos-sales@belden.com

The information published in the websites has been compiled as carefully as possible. It is subject to alteration without notice in technical as well as in price-related/commercial respect. The complete information and data were available on user documentation. Mandatory information can only be obtained by a concrete query.