
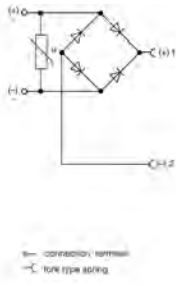




## Product information GDME GB1

Industrial Connecting Solutions:Rectangular Connectors:Valve Connectors (Type A -B -C):Type A:Field Attachable Valve Connectors:Electronic inserts for GDME:GDME GB1

<http://www.e-catalog.beldensolutions.com/link/57078-24228-256261-256266-256270-276215-24315-35674/en/conf/ui/state>

Name	GDME GB1
	
	bridge-type rectifier with protective circuit (varistor)
<b>Delivery informations</b>	
Availability	available
<b>Product description</b>	
Description	bridge-type rectifier with protective circuit (varistor)
Type	GDME GB1
Order No.	831 832-001
Standard	DIN EN 175 301-803-A
Construction type	A
<b>Description of Wiring</b>	
Voltage rectifier	bridge-type rectifier
Suppressor	varistor
<b>Technical data</b>	
Rated voltage	AC/DC 250 V
Rated current	2 A (SEV 1011 : 1.5 A) AC / 1 A DC
<b>Environmental conditions</b>	
Temperature range	-40 °C to +110 °C
<b>Packing unit</b>	
Packaging unit	50 pieces
<b>Picture</b>	
Drawing	

Belden Deutschland GmbH

Im Gewerbepark 2

58579 Schalksmühle

Germany

Phone: +49 7127/14-1806

The information published in the websites has been compiled as carefully as possible. It is subject to alteration without notice in technical as well as in price-related/commercial respect. The complete information and data were available on user documentation. Mandatory information can only be obtained by a concrete query.