
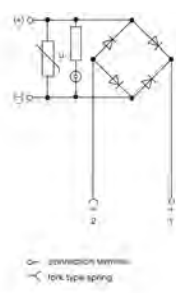


Product information

GDME GB1 LG 230

Industrial Connecting Solutions:Rectangular Connectors:Valve Connectors (Type A -B -C):Type A:Field Attachable Valve Connectors:Electronic inserts for GDME:GDME GB1 LG 230

<http://www.e-catalog.beldensolutions.com/link/57078-24228-256261-256266-256270-276215-24315-35673/en/conf/ui/state>

Name	GDME GB1 LG 230
	
	bridge-type rectifier with protective circuit (varistor) and function indicator (glow lamp)
Delivery informations	
Availability	available
Product description	
Description	bridge-type rectifier with protective circuit (varistor) and function indicator (glow lamp)
Type	GDME GB1 LG 230
Order No.	831 834-001
Standard	DIN EN 175 301-803-A
Construction type	A
Description of Wiring	
LED color	glow lamp
Voltage rectifier	bridge-type rectifier
Suppressor	varistor
Technical data	
Rated voltage	AC/DC 250 V
Rated current	2 A (SEV 1011 : 1.5 A) AC / 1 A DC
Environmental conditions	
Temperature range	-40 °C to +110 °C
Packing unit	
Packaging unit	50 pieces
Picture	
Drawing	



HIRSCHMANN

A **BELDEN** BRAND

Germany

Phone: +49 7127/14-1806

E-Mail: icos-sales@belden.com

The information published in the websites has been compiled as carefully as possible. It is subject to alteration without notice in technical as well as in price-related/commercial respect. The complete information and data were available on user documentation. Mandatory information can only be obtained by a concrete query.