



HIRSCHMANN

A BELDEN BRAND

Product information GDME LED 24 YE

Industrial Connecting Solutions:Rectangular Connectors:Valve Connectors (Type A -B -C):Type A:Field Attachable Valve Connectors:Electronic inserts for GDME:GDME LED 24 YE

<http://www.e-catalog.beldensolutions.com/link/57078-24228-256261-256266-256270-276215-24315-35669/en/conf/uistate>

Name GDME LED 24 YE



function indicator (LED) with freewheeling diode

Delivery informations

Availability available

Product description

Description function indicator (LED) with freewheeling diode

Type GDME LED 24 YE

Order No. 831 863-001

Standard DIN EN 175 301-803-A

Construction type A

Description of Wiring

LED color LED yellow

Technical data

Rated voltage AC/DC 24 V

Rated current 8 A

Environmental conditions


Temperature range -40 °C to +110 °C

Packing unit

Packaging unit 50 pieces

Picture

Drawing

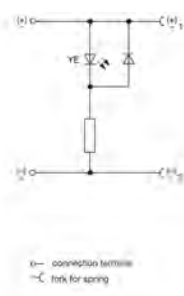

Belden Deutschland GmbH

Im Gewerbepark 2

58579 Schalksmühle

Germany

Phone: +49 7127/14-1806

E-Mail: icos-sales@belden.com

The information published in the websites has been compiled as carefully as possible. It is subject to alteration without notice in technical as well as in price-related/commercial respect.
The complete information and data were available on user documentation. Mandatory information can only be obtained by a concrete query.