
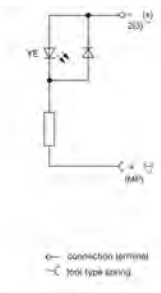


Product information

GDME HDL 24 YE

Industrial Connecting Solutions:Rectangular Connectors:Valve Connectors (Type A -B -C):Type A:Field Attachable Valve Connectors:Electronic inserts for GDME:GDME HDL 24 YE

<http://www.e-catalog.beldensolutions.com/link/57078-24228-256261-256266-256270-276215-24315-35671/en/conf/ui/state>

Name	GDME HDL 24 YE
	
	function indicator (LED) with freewheeling diode
Delivery informations	
Availability	available
Product description	
Description	function indicator (LED) with freewheeling diode
Type	GDME HDL 24 YE
Order No.	832 028-001
Standard	DIN EN 175 301-803-A
Construction type	A
Description of Wiring	
LED color	LED yellow
Other characteristics	pressure switch
Technical data	
Rated voltage	AC/DC 24 V
Rated current	8 A
Environmental conditions	
Temperature range	-40 °C to +110 °C
Packing unit	
Packaging unit	50 pieces
Picture	
Drawing	

Belden Deutschland GmbH
 Im Gewerbepark 2
 58579 Schalksmühle
 Germany
 Phone: +49 7127/14-1806

The information published in the websites has been compiled as carefully as possible. It is subject to alteration without notice in technical as well as in price-related/commercial respect. The complete information and data were available on user documentation. Mandatory information can only be obtained by a concrete query.