



Product information MAK 80 S grau/grey

Industrial Connecting Solutions: Circular Connectors: Audio/Video Connectors: DIN EN 60 130-09 Connectors (MAS/MAK series): without locking screw: Straight sockets: MAK 80 S grau/grey

<http://www.e-catalog.beldensolutions.com/link/57078-24228-256281-256282-24384-24385-24390-34454/en/conf/uistate>

Name MAK 80 S grau/grey



socket with insulated handle; solder joint

Delivery informations

Availability available

Product description

Type MAK 80 S grau/grey

Order No. 930 348-517

Type of contact female

Description socket with insulated handle; solder joint

Housing Color grey

Number of contacts 8

Conductor size $\leq 0.34 \text{ mm}^2$

Technical data

LF output "Phone" EN 60 130-09

Pole arrangement DIN DIN 41 524 (sockets 1-5)

Rated current 4 A

Rated voltage AC/DC 34 V

Cable diameter 5.5 mm

Type of termination solder

Material

Contact material (socket) brass

Contact surface material tin plated

Contact bearer material PA 66/UL standard 94V-2

Housing material PE

Environmental conditions

Protection class (IEC 60529) IP 30


Temperature range -20 °C to +60 °C

Scope of delivery and accessories

Packaging retail package, polyethylene bag

Picture

Drawing

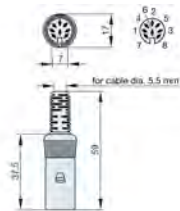



HIRSCHMANN

A **BELDEN** BRAND

Belden Deutschland GmbH

Im Gewerbepark 2

58579 Schalksmühle

Germany

Phone: +49 7127/14-1806

E-Mail: icos-sales@belden.com

The information published in the websites has been compiled as carefully as possible. It is subject to alteration without notice in technical as well as in price-related/commercial respect. The complete information and data were available on user documentation. Mandatory information can only be obtained by a concrete query.