
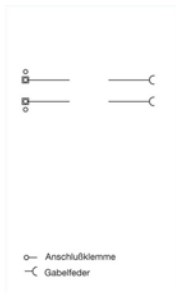


Product information GDME UV 1

Industrial Connecting Solutions:Rectangular Connectors:Valve Connectors (Type A -B -C):Type A:Field Attachable Valve Connectors:Electronic inserts for GDME:GDME UV 1

<http://www.e-catalog.beldensolutions.com/link/57078-24228-256261-256266-256270-276215-24315-35677/en/conf/uistate>

| Name | |
|--------------------------|---|
| GDME UV 1 | |
| |  |
| | unequipped circuit board with 2 fork type springs and 2 clamping box |
| Delivery informations | |
| Availability | available |
| Product description | |
| Description | unequipped circuit board with 2 fork type springs and 2 clamping box |
| Type | GDME UV 1 |
| Order No. | 931 415-000 |
| Standard | DIN EN 175 301-803-A |
| Construction type | A |
| Technical data | |
| Rated current | 10 A |
| Environmental conditions | |
| Temperature range | -40 °C to +110 °C |
| Packing unit | |
| Packaging unit | 50 pieces |
| Picture | |
| Drawing |  |

Belden Deutschland GmbH
Im Gewerbepark 2
58579 Schalksmühle
Germany
Phone: +49 7127/14-1806
E-Mail: icos-sales@belden.com

The information published in the websites has been compiled as carefully as possible. It is subject to alteration without notice in technical as well as in price-related/commercial respect.
The complete information and data were available on user documentation. Mandatory information can only be obtained by a concrete query.