



# HIRSCHMANN

A BELDEN BRAND

## Product information MAB 8 SN

Industrial Connecting Solutions: Circular Connectors: Audio/Video Connectors: DIN EN 60 130-09 Connectors (MAS/MAK series): without locking screw: Panel-mounted sockets: MAB 8 SN

<http://www.e-catalog.beldensolutions.com/link/57078-24228-256281-256282-24384-24385-24386-34460/en/conf/ui/state>

Name MAB 8 SN



panel-mounted socket with flange; solder joint

### Delivery informations

Availability available

### Product description

Type MAB 8 SN

Order No. 931 613-200

Type of contact female

Description panel-mounted socket with flange; solder joint

Number of contacts 8

Conductor size  $\leq 0.34 \text{ mm}^2$

### Technical data

LF output "Phone" EN 60 130-09

Pole arrangement DIN DIN 45 326

Rated current 4 A

Rated voltage AC/DC 34 V

Type of termination solder

### Material

Contact material (socket) brass

Contact surface material tin plated

Contact bearer material PA 66/UL standard 94V-2

Housing material steel, nickel-plated


### Environmental conditions

Protection class (IEC 60529) IP 30

Temperature range -20 °C to +60 °C

### Picture

Drawing

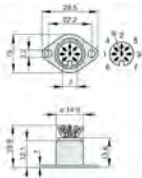



# HIRSCHMANN

A **BELDEN** BRAND

**Belden Deutschland GmbH**

Im Gewerbepark 2  
58579 Schalksmühle  
Germany  
Phone: +49 7127/14-1806  
E-Mail: [icos-sales@belden.com](mailto:icos-sales@belden.com)

The information published in the websites has been compiled as carefully as possible. It is subject to alteration without notice in technical as well as in price-related/commercial respect. The complete information and data were available on user documentation. Mandatory information can only be obtained by a concrete query.