




Product information CA 6 GD


Industrial Connecting Solutions: Circular Connectors: MIL, DIN, Universal Connectors: Signal and Power (CA series): Cable socket and panel-mounted socket: CA 6 GD

<http://www.e-catalog.beldensolutions.com/link/57078-24228-256281-256284-24359-24360-36075/en/conf/ui/state>

| | |
|--|---|
| Name | CA 6 GD |
| |  |
| | Panel-mounted socket with flange |
| Delivery informations | |
| Availability | available |
| Product description | |
| Description | Panel-mounted socket with flange |
| Type | CA 6 GD |
| Order No. | 932 325-100 |
| Number of contacts | 6 + PE |
| Cable diameter | 6 mm to 12 mm |
| Conductor size | max. 0.75 mm ² |
| Housing Color | black |
| Technical data | |
| Pin dimensions | 1.5 mm |
| Rated voltage | AC/DC 250 V |
| Rated current | 10 A AC/DC |
| Contact resistance | <= 5 mOhm |
| Type of termination | solder, concave pins |
| Mounting | flange |
| Material | |
| Contact surface material | Ag |
| Contact bearer material | PA 66-GF 25 |
| Housing material | PA 66-GF 25 |
| O-Ring | NBR |
| Environmental conditions | |
| Protection class (IEC 60529) | IP 67 |
| Pollution severity | 3 |
| Temperature range | -40 °C to +90 °C |
| Inflammability class | |
| Flammability, UL standard | 94 V-0 |
| Approvals | |
| UL | UL |
| VDE | VDE |
| Packaging unit | |
| Packaging unit | 100 pieces |
| Scope of delivery and accessories | |
| Scope of delivery | 1 panel-mounted socket with sealing ring, in polyphene bag |
| Accessories to order separately | can be plugged into CA 6 LS; cap CA 00 SD 4, order no. 831 531-100 |

Picture

Drawing

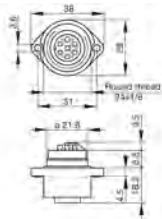

Belden Deutschland GmbH

Im Gewerbepark 2
58579 Schalksmühle
Germany
Phone: +49 7127/14-1806
E-Mail: icos-sales@belden.com

The information published in the websites has been compiled as carefully as possible. It is subject to alteration without notice in technical as well as in price-related/commercial respect. The complete information and data were available on user documentation. Mandatory information can only be obtained by a concrete query.