




## Product information ELKE 512 PG9 Au

Industrial Connecting Solutions:Archive - Industrial Connectors:Circular Connectors E-series M12 / M12 push-pull (Archive):with screw locking:Appliance socket for front panel - front panel  
mounting:ELKE 512 PG9 Au

<http://www.e-catalog.beldensolutions.com/link/57078-24228-62529-24256-24257-24273-36774/en/conf/uistate>


|  |  |
|--|--|
| Name                                     | ELKE 512 PG9 Au  |
|  |                       |
|  | Screw-in appliance socket, PG 9 front mounting thread, with wire ends, screw locking, O-ring included  |
| <b>Delivery informations</b>             |  |
| Availability                             | no longer available  |
| <b>Product description</b>               |  |
| Description                              | Screw-in appliance socket, PG 9 front mounting thread, with wire ends, screw locking, O-ring included  |
| Type                                     | ELKE 512 PG9 Au  |
| Order No.                                | 933 040-100  |
| Type of contact                          | female   |
| Number of contacts                       | 5  |
| Cable material                           | PVC  |
| Cable length                             | 0.2 m  |
| Conductor size                           | 0.34 mm <sup>2</sup>   |
| Standard                                 | IEC 61076-2-101 (Ed. 1)/ IEC 60947-5-2   |
| Housing Color                            | metallic   |
| <b>Technical data</b>                    |  |
| Wire stranding                           | 7 x 0.25 mm  |
| Rated voltage                            | AC/DC 50 V   |
| Rated current                            | 4 A  |
| <b>Material</b>                          |  |
| Contact material                         | Cu Zn  |
| Contact surface material                 | Au   |
| Contact bearer material                  | PA   |
| Housing material                         | Cu Zn/Ni   |
| O-Ring                                   | NBR  |
| <b>Environmental conditions</b>          |  |
| Protection class (IEC 60529)             | IP 67  |
| Pollution severity                       | 3  |
| Temperature range                        | -25 °C to +90 °C   |
| <b>Inflammability class</b>              |  |
| Contact bearer                           | 94 V-2   |
| <b>Approvals</b>                         |  |
| UL                                       | UL   |
| <b>Packing unit</b>                      |  |
| Packaging unit                           | 100 pieces   |
| <b>Scope of delivery and accessories</b> |  |
| Accessories to order separately          | protective cap M12 VS,<br>order no. 734 209-100;<br>fastening nut ELST M PG9,<br>order no. 733 877-001 |

Industrial Connecting Solutions:Archive - Industrial Connectors:Circular Connectors E-series M12 / M12 push-pull (Archive):with screw locking:Appliance socket for front panel - front panel  
mounting:ELKE 512 PG9 Au

<http://www.e-catalog.beldensolutions.com/link/57078-24228-62529-24256-24257-24273-36774/en/conf/uistate>

Picture

Drawing

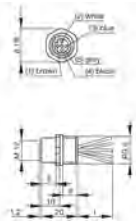

**Belden Deutschland GmbH**  
Im Gewerbepark 2  
58579 Schalksmühle  
Germany  
Phone: +49 7127/14-1806  
E-Mail: [icos-sales@belden.com](mailto:icos-sales@belden.com)

The information published in the websites has been compiled as carefully as possible. It is subject to alteration without notice in technical as well as in price-related/commercial respect. The complete information and data were available on user documentation. Mandatory information can only be obtained by a concrete query.