



## Product information N11R BM FA F Kunststoff/plastics

Industrial Connecting Solutions: Circular Connectors: MIL, DIN, Universal Connectors: DIN 43651 Connectors (NR series): Surface mounted connector: N11R BM FA F Kunststoff/plastics

<http://www.e-catalog.beldensolutions.com/link/57078-24228-256281-256284-24367-24373-39798/en/conf/ui/state>

Name N11R BM FA F Kunststoff/plastics



Surface-mounted connector with flange and filter selection 11 x 1nF,

### Delivery informations

Availability available

### Product description

Description Surface-mounted connector with flange and filter selection 11 x 1nF,

Type N11R BM FA F Kunststoff/plastics

Order No. 933 100-100

Type of contact male

Number of contacts 11 + PE

Housing Color black

### Technical data

Pin dimensions 1.6 mm

Rated voltage AC 25 V / DC 50 V

Rated current 5 A

Contact resistance  $\leq 5 \text{ m}\Omega$

Type of termination solder, solid pins

Mounting flange

### Material

Contact surface material Ag

Contact bearer material PET

Housing material Zn Al/Ni

### Environmental conditions

Protection class (IEC 60529) IP 65

Temperature range  $-40 \text{ }^\circ\text{C}$  to  $+90 \text{ }^\circ\text{C}$

### Packing unit


Packaging unit 50 pieces

### Scope of delivery and accessories

Accessories to order separately can be plugged into N11R EF S;  
protective cover SHK 2,  
order no. 733 845-001

### Picture

#### Drawing

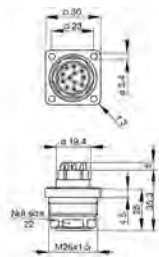



**HIRSCHMANN**

A **BELDEN** BRAND

**Belden Deutschland GmbH**

Im Gewerbepark 2

58579 Schalksmühle

Germany

Phone: +49 7127/14-1806

E-Mail: [icos-sales@belden.com](mailto:icos-sales@belden.com)

The information published in the websites has been compiled as carefully as possible. It is subject to alteration without notice in technical as well as in price-related/commercial respect. The complete information and data were available on user documentation. Mandatory information can only be obtained by a concrete query.