




Product information GMNL-K 2000 LED 24 GB1 ZZ 5m schwarz/black

Industrial Connecting Solutions:Archive - Industrial Connectors:Rectangular connectors GDM-series (Archive):Type B EN 175301-803 (DIN 43650) / ISO 6952 (Archive):Molded cable socket

(Archive):GMNL-K 2000 LED 24 GB1 ZZ 5m schwarz/black

<http://www.e-catalog.beldensolutions.com/link/57078-24228-62529-86162-86212-86214-35365/en/conf/ui/state>

Name	GMNL-K 2000 LED 24 GB1 ZZ 5m schwarz/black
	
	cable socket with molded-on-lead, rectifier with protective circuit (Z-diode) and function indicator (LED)
Delivery informations	
Availability	no longer available
Product description	
Description	cable socket with molded-on-lead, rectifier with protective circuit (Z-diode) and function indicator (LED)
Type	GMNL-K 2000 LED 24 GB1 ZZ 5m schwarz/black
Order No.	933 249-112
Other standard types	transparent housing, coding plate black: cable length 2 m, Order No. 933 249-111; coding plate grey: cable length 2 m, Order No. 933 249-611; cable length 5 m, Order No. 933 249-612
Number of contacts	2 + PE
Cable material	PVC
Cable length	5 m
Cable diameter	6.5 mm
Conductor size	0.75 mm ²
Cable specification	3 x 0.75 mm ² (PVC, grey)
Cable type	following VDE 0281-5 / H03 VV-F
Standard	DIN EN 175 301-803-B
Housing Color	transparent, coding plate black
Construction type	B
Description of Wiring	
LED color	LED yellow
Voltage rectifier	for LED
Suppressor	Z-Diode
Technical data	
Pin dimensions	6.3 mm x 0.8 mm
Wire stranding	42 x 0.15
Rated voltage	AC/DC 24 V
Rated current	8 A
Contact resistance	<= 4 mOhm
Mounting	central screw
Material	
Contact surface material	Sn
Contact bearer material	PA
Housing material	PA
Environmental conditions	
Protection class (IEC 60529)	IP 65 (IP 67 on request)
Pollution severity	3
Temperature range	-25 °C to +80 °C
Inflammability class	
Housing	94 HB
Cable	according to VDE 0482-265-2
Contact bearer	94 HB



HIRSCHMANN

A BELDEN BRAND

Industrial Connecting Solutions:Archive - Industrial Connectors:Rectangular connectors GDM-series (Archive):Type B EN 175301-803 (DIN 43650) / ISO 6952 (Archive):Molded cable socket

(Archive):GMNL-K 2000 LED 24 GB1 ZZ 5m schwarz/black

<http://www.e-catalog.beldensolutions.com/link/57078-24228-62529-86162-86212-86214-35365/en/conf/uistate>

Packing unit


Packaging unit 25 pieces

Scope of delivery and accessories

Accessories to order separately (NBR) flat gasket GMN 209-3, Order No. 733 273-002; knurled screw GDM 3011-8, Order No. 732 574-001; stainless steel screw GDM 3011 RF-1, Order No. 734 363-001

Picture

Drawing

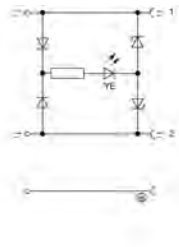

Belden Deutschland GmbH

Im Gewerbepark 2
58579 Schalksmühle
Germany
Phone: +49 7127/14-1806
E-Mail: icos-sales@belden.com

The information published in the websites has been compiled as carefully as possible. It is subject to alteration without notice in technical as well as in price-related/commercial respect. The complete information and data were available on user documentation. Mandatory information can only be obtained by a concrete query.