



HIRSCHMANN


A BELDEN BRAND

Product information GMNL 209 NJ LED 24 HH schwarz/black

Industrial Connecting Solutions:Rectangular Connectors:Valve Connectors (Type A -B -C):Type B:Field Attachable Valve Connectors:Valve Connectors with electronic insert (DIN EN 175 301-803):GMNL

209 NJ LED 24 HH schwarz/black

<http://www.e-catalog.beldensolutions.com/link/57078-24228-256261-256266-256271-276218-24322-35328/en/conf/uistate>

Name	GMNL 209 NJ LED 24 HH schwarz/black
	
function indicator (LED) with protective circuit (diode)	
Delivery informations	
Availability	available
Product description	
Description	function indicator (LED) with protective circuit (diode)
Type	GMNL 209 NJ LED 24 HH schwarz/black
Order No.	933 388-100
Other standard types	transparent housing, cable gland grey: Order No. 933 388-106
Number of contacts	2 + PE
Cable gland	PG 9 (black)
Cable diameter	6.5 mm
Conductor size	max. 1.5 mm ²
Standard	DIN EN 175 301-803-B
Housing Color	transparent
Construction type	B
Description of Wiring	
LED color	LED red
Suppressor	diode
Technical data	
Pin dimensions	6.3 mm x 0.8 mm
Rated voltage	DC 24 V
Rated current	8 A
Contact resistance	<= 4 mOhm
Type of termination	screw / cable shoe / cable eye
Suitable cables	4.5 mm to 7 mm diameter
Mounting	central screw
Material	
Contact surface material	Sn
Contact bearer material	PA
Housing material	PA
Environmental conditions	
Protection class (IEC 60529)	IP 65
Pollution severity	3
Temperature range	-40 °C to +90 °C
Inflammability class	
Housing	94 V-1
Contact bearer	94 HB
Approvals	
UR	UR
Packing unit	
Packaging unit	50 pieces

Industrial Connecting Solutions:Rectangular Connectors:Valve Connectors (Type A -B -C):Type B:Field Attachable Valve Connectors:Valve Connectors with electronic insert (DIN EN 175 301-803):GMNL

209 NJ LED 24 HH schwarz/black


<http://www.e-catalog.beldensolutions.com/link/57078-24228-256261-256266-256271-276218-24322-35328/en/conf/uistate>

Scope of delivery and accessories

Accessories to order separately (NBR) flat gasket GDM 209-3, Order No. 733 273-002; knurled screw GDM 3011-8, Order No. 732 574-001; stainless steel screw GDM 3011 RF-1, Order No. 734 363-001

Picture

Drawing

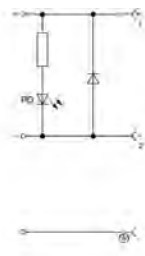

Belden Deutschland GmbH

Im Gewerbepark 2
58579 Schalksmühle
Germany
Phone: +49 7127/14-1806
E-Mail: icos-sales@belden.com

The information published in the websites has been compiled as carefully as possible. It is subject to alteration without notice in technical as well as in price-related/commercial respect. The complete information and data were available on user documentation. Mandatory information can only be obtained by a concrete query.