



Product information GMNL 209 NJ LED 120 YE schwarz/black

Industrial Connecting Solutions:Rectangular Connectors:Valve Connectors (Type A -B -C):Type B:Field Attachable Valve Connectors:Valve Connectors with electronic insert (DIN EN 175 301-803):GMNL 209 NJ LED 120 YE schwarz/black

<http://www.e-catalog.beldensolutions.com/link/57078-24228-256261-256266-256271-276218-24322-35332/en/conf/ui/state>

| | |
|--|---|
| Name | GMNL 209 NJ LED 120 YE schwarz/black |
| |  |
| | function indicator (LED) with freewheeling diode |
| Delivery informations | |
| Availability | available |
| Product description | |
| Description | function indicator (LED) with freewheeling diode |
| Type | GMNL 209 NJ LED 120 YE schwarz/black |
| Order No. | 933 714-100 |
| Other standard types | transparent housing, cable gland grey; Order No. 933 714-106 |
| Number of contacts | 2 + PE |
| Cable gland | PG 9 (black) |
| Cable diameter | 6.5 mm |
| Conductor size | max. 1.5 mm ² |
| Standard | DIN EN 175 301-803-B |
| Housing Color | transparent |
| Construction type | B |
| Description of Wiring | |
| LED color | LED yellow |
| Technical data | |
| Pin dimensions | 6.3 mm x 0.8 mm |
| Rated voltage | AC/DC 120 V |
| Rated current | 8 A |
| Contact resistance | <= 4 mOhm |
| Type of termination | screw / cable shoe / cable eye |
| Suitable cables | 4.5 mm to 7 mm diameter |
| Mounting | central screw |
| Material | |
| Contact surface material | Sn |
| Contact bearer material | PA |
| Housing material | PA |
| Environmental conditions | |
| Protection class (IEC 60529) | IP 65 |
| Pollution severity | 3 |
| Temperature range | -40 °C to +90 °C |
| Inflammability class | |
| Housing | 94 V-1 |
| Contact bearer | 94 HB |
| Approvals | |
| UR | UR |
| Packing unit | |
| Packaging unit | 50 pieces |
| Scope of delivery and accessories | |
| Accessories to order separately | (NBR) flat gasket GMN 209-3, Order No. 733 273-002; knurled screw GDM 3011-8, Order No. 732 574-001; stainless steel screw GDM 3011 RF-1, Order No. 734 363-001 |


Industrial Connecting Solutions:Rectangular Connectors:Valve Connectors (Type A -B -C):Type B:Field Attachable Valve Connectors:Valve Connectors with electronic insert (DIN EN 175 301-803):GMNL

209 NJ LED 120 YE schwarz/black

<http://www.e-catalog.beldensolutions.com/link/57078-24228-256261-256266-256271-276218-24322-35332/en/conf/uistate>

Picture

Drawing

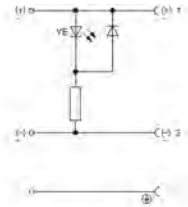

Belden Deutschland GmbH

Im Gewerbepark 2

58579 Schalksmühle

Germany

Phone: +49 7127/14-1806

E-Mail: icos-sales@belden.com

The information published in the websites has been compiled as carefully as possible. It is subject to alteration without notice in technical as well as in price-related/commercial respect. The complete information and data were available on user documentation. Mandatory information can only be obtained by a concrete query.